


Wypychacz odsadzany hartowany

Step pin hardened

OH

DIN 1530-2 / ISO 8694

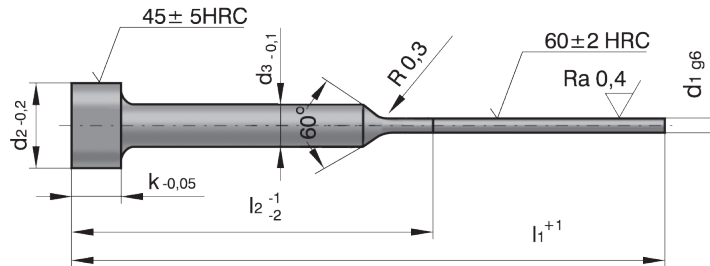

Uwaga: Dostępne także z powłoką DLC
W celu zamówienia skontaktuj się z nami.
 Note: DLC coating available. Contact FCPK for details.

Mat.: Stal narzędziowa Tool steel 250°C

d1	d2	d3	k	NR KAT.				
				l2=35	l2=50	l2=50	l2=75	l2=75
				l1=80	l1=100	l1=125	l1=160	l1=200
0,8	4	2	2	OH - 080080	OH - 080100	OH - 080125	OH - 080160	
0,9				OH - 090080	OH - 090100	OH - 090125	OH - 090160	
1,0				OH - 100080	OH - 100100	OH - 100125	OH - 100160	
1,1				OH - 110080	OH - 110100	OH - 110125	OH - 110160	
1,2				OH - 120080	OH - 120100	OH - 120125	OH - 120160	
1,3				OH - 130080	OH - 130100	OH - 130125	OH - 130160	
1,4				OH - 140080	OH - 140100	OH - 140125	OH - 140160	
1,5				OH - 150080	OH - 150100	OH - 150125	OH - 150160	OH - 150200
1,6	6	3	3	OH - 160080	OH - 160100	OH - 160125	OH - 160160	OH - 160200
1,7				OH - 170080	OH - 170100	OH - 170125	OH - 170160	OH - 170200
1,8				OH - 180080	OH - 180100	OH - 180125	OH - 180160	OH - 180200
1,9				OH - 190080	OH - 190100	OH - 190125	OH - 190160	OH - 190200
2,0				OH - 200080	OH - 200100	OH - 200125	OH - 200160	OH - 200200
2,1				OH - 210080	OH - 210100	OH - 210125	OH - 210160	OH - 210200
2,2				OH - 220080	OH - 220100	OH - 220125	OH - 220160	OH - 220200
2,3				OH - 230080	OH - 230100	OH - 230125	OH - 230160	OH - 230200
2,4				OH - 240080	OH - 240100	OH - 240125	OH - 240160	OH - 240200
2,5					OH - 250100	OH - 250125	OH - 250160	OH - 250200
2,6					OH - 260100	OH - 260125	OH - 260160	OH - 260200
2,7					OH - 270100	OH - 270125	OH - 270160	OH - 270200
2,8					OH - 280100	OH - 280125	OH - 280160	OH - 280200
2,9					OH - 290100	OH - 290125	OH - 290160	OH - 290200

Uwaga. Inne wymiary na zapytanie
 Note. Other dimensions on request.