

Bestellbezeichnung (Beispiel)
Order specification (example)
Référence de commande (exemple)

EZ 251 .25 / 16. 01. 201. 25


Kolben Ø Piston Ø Rod Ø Ø Tige (d)	Befestigungsart Mounting mode Mode de fixation	Funktionsart Operation mode Mode de fonctionnement	Hub	Stroke	Course	Option Option Option	L1	L2	L3	L4	L5	L6	L7	L8	D1	D2	
20	12	01	201	10	20	30	V	39	7	47	31	7	10	20,5	33	37	12
25	16	01	201	10	25	50		49	7	57	39	10	13	25,5	40	44	16
32	20	01	201	16	32	50		51	10	62	44	12	15	28,5	40	54	20
40	25	01	201	20	40	60		59	12	72	47	14	16	30,5	46	65	25

Technische Änderungen vorbehalten
Subject to change without notice
Sous réserve de modifications

Maße in mm
Dimensions in mm
Dimensions en mm

Berechnungsgrundlage siehe ahp informiert
Calculation based on "Information from AHP"
Base de calcul, voir « AHP vous informe »

Technische Informationen Technical information Informations techniques

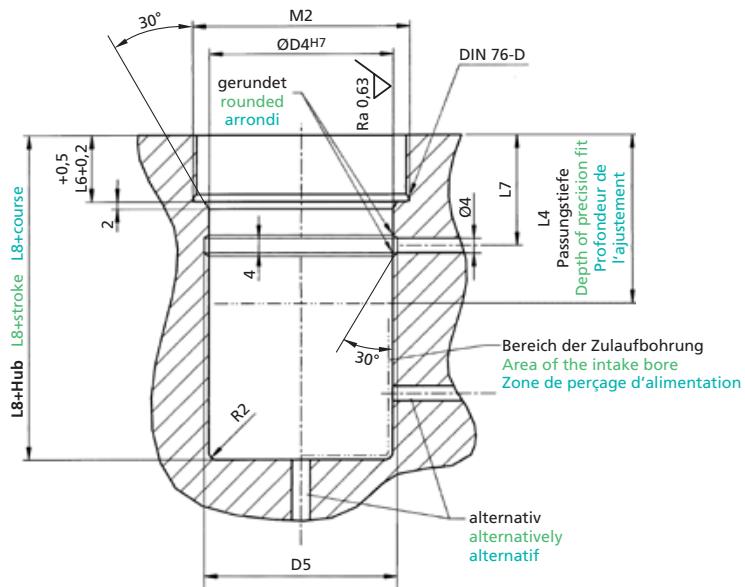

D3	D4f7	D5	M1 x Tiefe M1 x depth M1 x profondeur	M2
26	28	29	M8x12	M32x1,5
33	35	36	M10x15	M40x1,5
42	44	46	M12x20	M50x1,5
53	55	57	M16x25	M60x1,5