


密封扣/旋转扣



■大型门用·拔插型

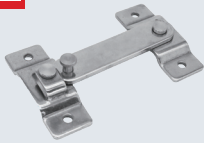

①代号	类型	④材质	⑤表面处理
MKSSHA	拔插型	SUS304	电解研磨

规格: 28, 14, 4-R3, 5, 4, 80, 60, Ø11, 18, 27, 3, 2-Ø6, 15, 2, 3, 4, 14, 16, 22, 26, 80, 5, 3, 19, 10, 40, 25, 3

MKSSHA 视角标准: 第一视角



①代号 - ②L
MKSSHA - L100

型号	①代号	②L	参考重量 (kg/pcs)
MKSSHA		100	0.19
		150	0.22

 



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	现询

■中型门用·弹片锁定型

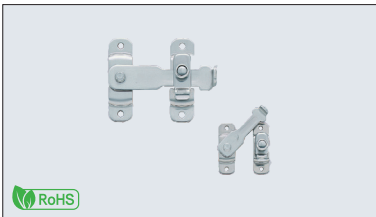

倒置
正置、倒置均可使用。
倒置安装时，只需一按即可脱开。

①代号	类型	④材质	⑤表面处理
MKSSLA	弹片式锁定	SUS304	震动抛光

规格: 45/60/80/100, 120

MKSSLA 视角标准: 第一视角



①代号 - ②规格
MKSSLA - 100

型号	S	S ₁	A	C	F	L	L ₁	H	H ₁	d	附件螺钉	参考重量 (kg/pcs)
MKSSLA	45	40	32	6.5	13	17	4.5	48	23±3	3.2	M3-L10	0.028
	60	46	37	8	16	20	6	63	34±7	4.2	M3.5-L16	0.05
	80	65	53	10	20	22.5	7	85	47±7	5	M4.5-L16	0.1
	100	80	66	12.5	25	26.5	8	105	59±7	5.5	M5-L20	0.182
	120	100	80	-	28.5	15	28	8	127	56±10	5.2	M5-L20



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	现询



爱安特自营商城焕新登场，线上下单，疾速送达



400-6699-428



www.ant-fa.com