


按图定制

①代号 <b>MALAGKT</b>	边长 25×25	④材质 铝合金	⑤表面处理 -	最高使用压力 1MPa(≈10.2Kgf/cm²)以下
-----------------------	-------------	------------	------------	--------------------------------

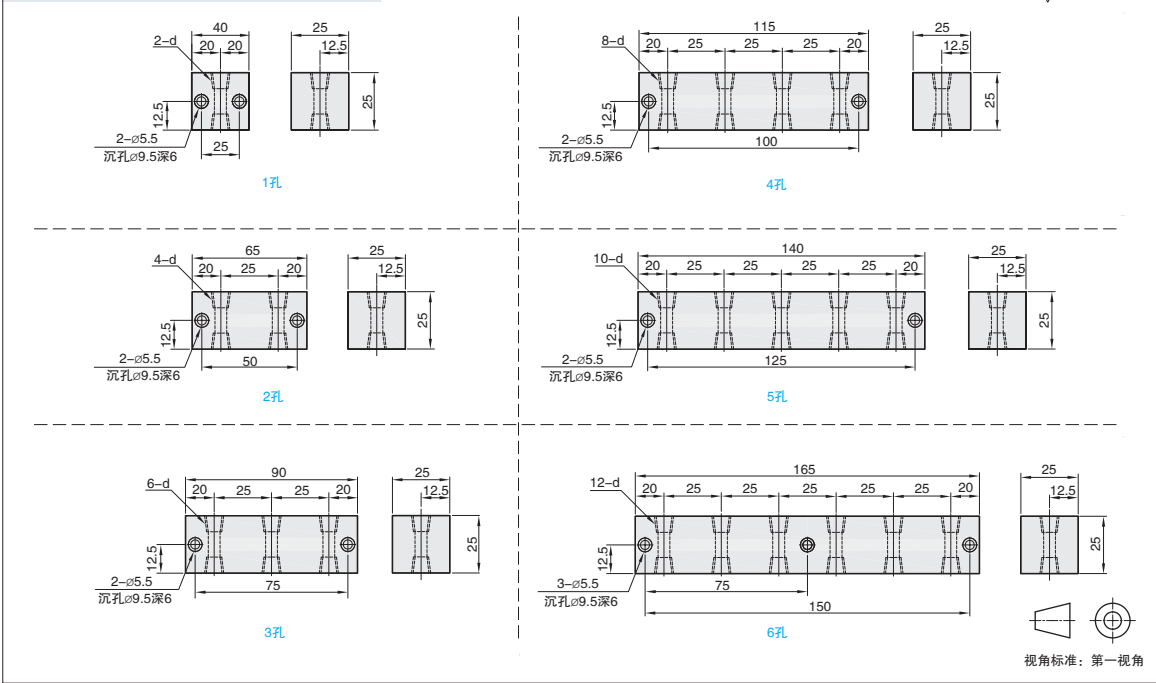

L5 歧管块



①代号 - ②侧面孔数K - ③螺纹代号L  
**MALAGKT** - **K2** - **L22**

①代号	②侧面孔数K		③螺纹代号L	d Rc(PT)
	K			
<b>MALAGKT</b> (25×25)	1	2	11	1/8
			22	1/4
			55	M5
	2	2	11	1/8
			22	1/4
			55	M5
	3	2	11	1/8
			22	1/4
			55	M5
	4	2	11	1/8
			22	1/4
			55	M5
	5	2	11	1/8
			22	1/4
			55	M5
	6	2	11	1/8
			22	1/4
			55	M5

▲ 螺纹代号: 如22, 表示d为1/4管螺纹。