


特殊弹簧柱塞

止动螺丝型

■ 止动螺丝型



负载分类	平头型	主体	销	弹簧	可使用温度
	轻载型 TPEBBP	[M] 材质	[M] 材质	[M] 材质	
重载型	TPEBFP	SUS303	SUS304	SUS304	-30°~140°C

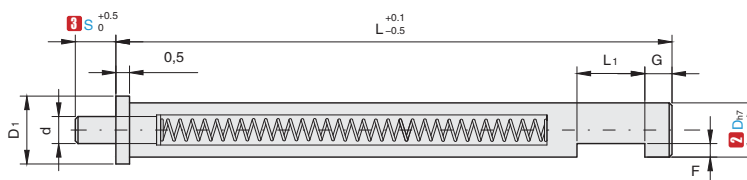

订购编号示例

① 代号	-	② D _{h7}	-	③ S
TPEBBP	-	D1.5	-	1.5

① 代号	② D _{h7}	③ S	d	D ₁	L	L ₁	F	G	C	轻载型	
										许用载荷 (N)	
										min.	max.
(平头型) TPEBBP TPEBFP	1.5	1.5	0.5	2	17.5	2.5	0.5	1	0.05	0.49	0.98
	2	1.5	1	2.5	20.5	2.5	0.5	1	0.1	0.49	0.98
		3			30.5					0.49	0.98
	3	3	2	3.5	20.5	2.5	0.5	1	0.15	0.49	1.47
		6			30.5					0.49	1.47
	4	3	3	4.5	20.5	3.5	0.8	1	0.2	0.59	1.47
					25.5					0.49	2.06
					37.5					0.69	3.92
	5	4	4	5.5	22.5	3.5	0.8	1	0.3	0.64	1.96
					29.5					0.78	3.82
					37.5					0.83	5.79

F5
弹簧柱塞

分类
目录



返回
主目录

