


防震支脚




★ 产品特点: 有较强的承载力和卓越的抗震性能。




①代号	形状	外壳M材质	螺杆	底部	⑤表面处理
SFFTZULA	圆形	HT200	45#	丁腈橡胶	镀锌
SFFTZULB	方形				

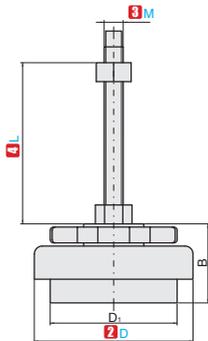

SFFTZULA

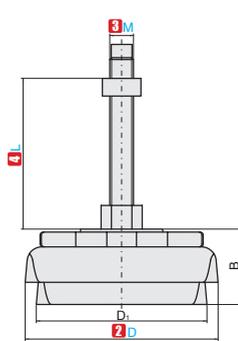

SFFTZULB

 

视角标准: 第一视角



①代号 - ②底径 - ③螺纹直径 - ④螺纹长度
SFFTZULA - D100 - M12 - L100

①代号	主要尺寸						承载(kg)	参考重量 (kg/pcs)
	②D	③M	④L	D _i	B	最大调整量		
铸铁 SFFTZULA	100	M12	75	80	50	25	200	1.7
			100					
			175					
	140	M16	75	120	52	28	600	3.2
			100					
			175					
190	M20	100	160	55	32	900	4.8	
		175						
		175						
铸铁 SFFTZULB	110	M12	75	100	47	15	150	2.0
			100					
	130	M16	75	115	51	20	280	3.3
			100					
	160	M16	100	150	65	24	600	4.2
			175					
200	M20	100	185	76	27	1200	6.0	
		175						

⚠ 承载与参考重量仅供参考。



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	另行报价

