
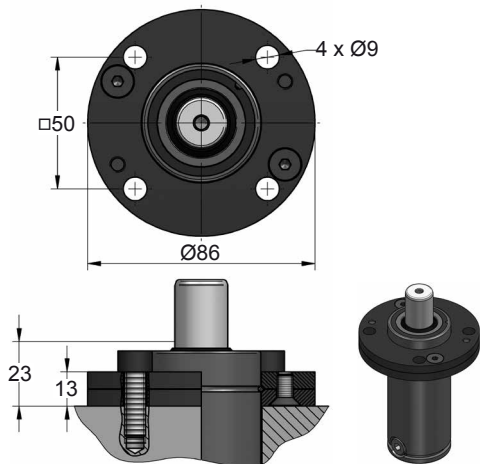
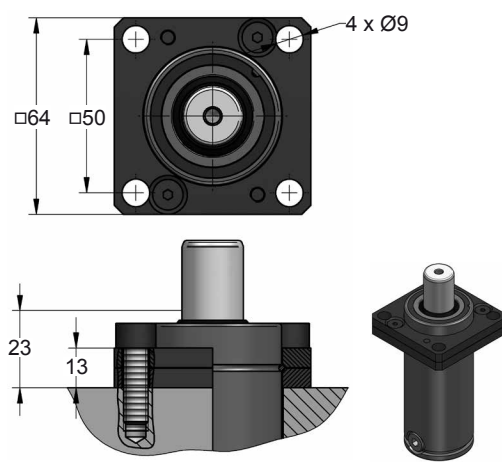
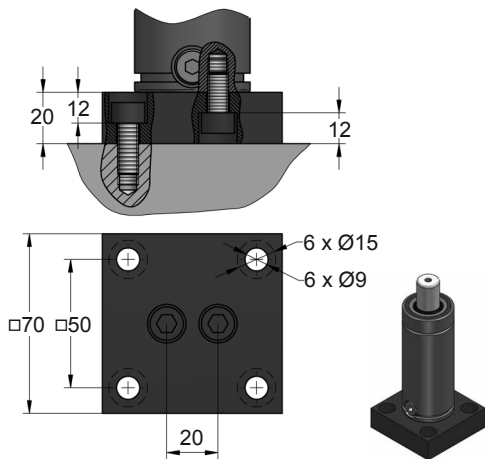
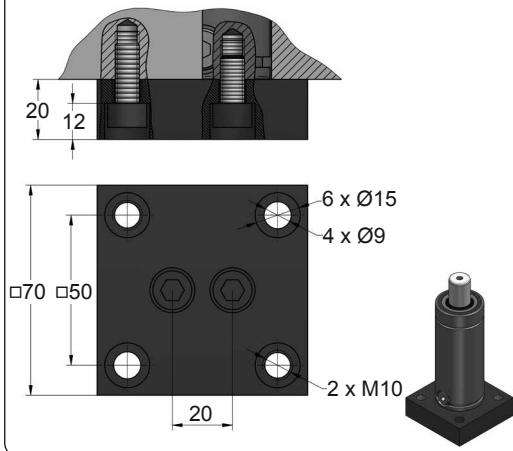



BRIDAS Ø 45**A14-045****A34-045****B21-045****B36-045**

B41-045

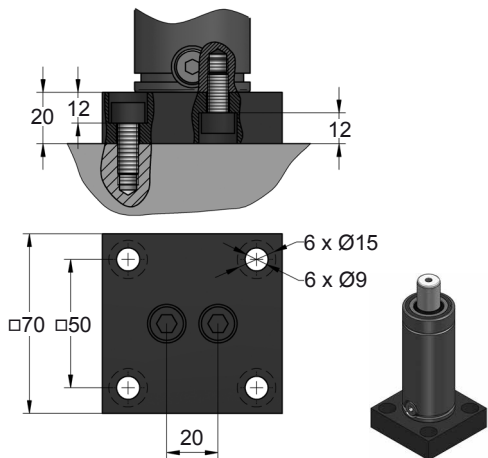


B43-045

K32 P0
EM24.54.700/F

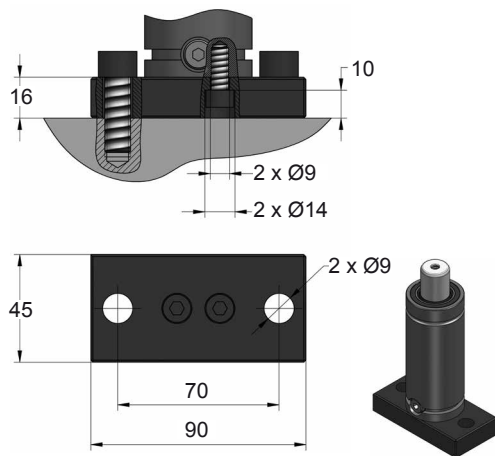










B51-045

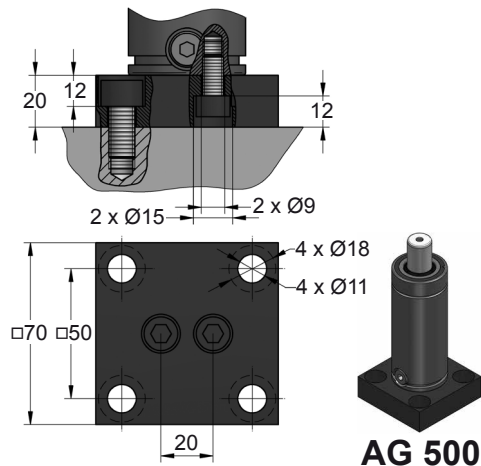

B76-045

ISO 9001 E24.54.815.G

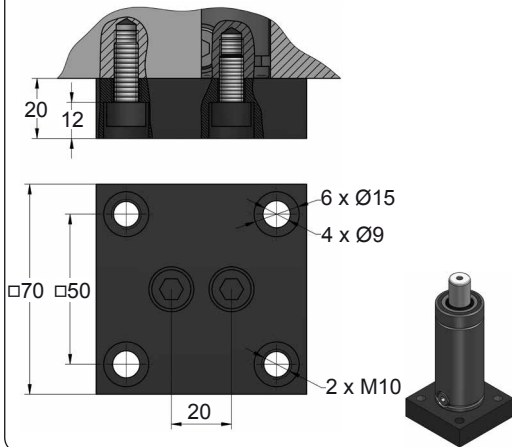

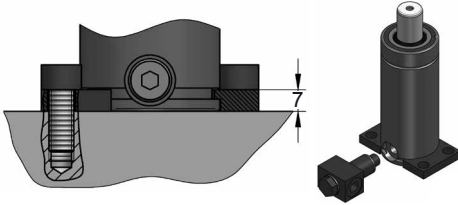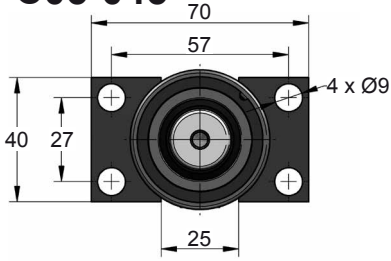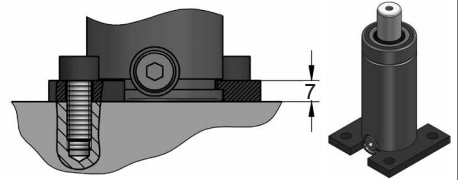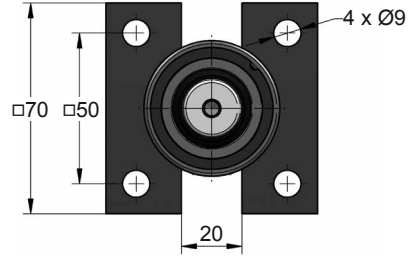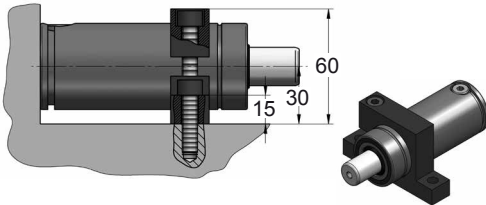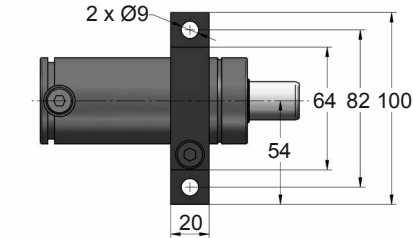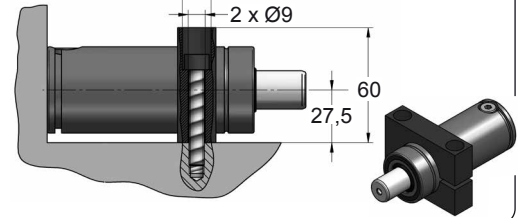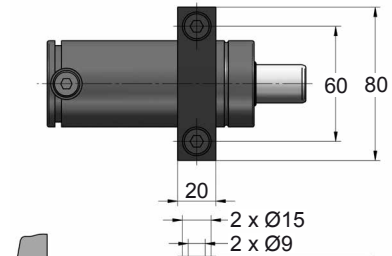BRIDAS Ø 45**AZOL
GAS** **C05-045****C20-045****D02-045****D67-045**

E03-045

