



AFH V1


Mini

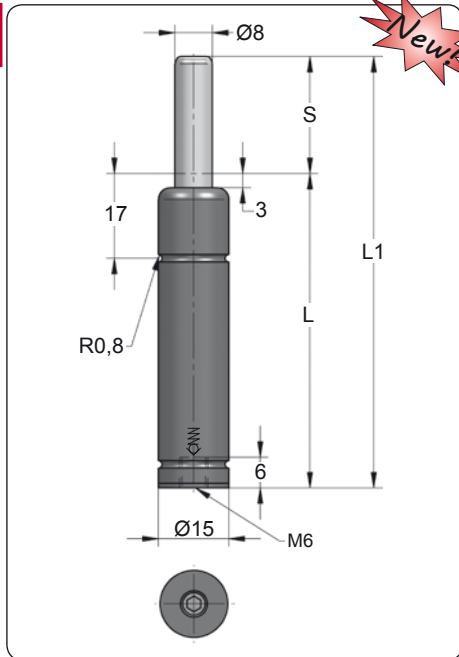

CODE	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
AFH ... 007 V1	7	56	49	0.06
AFH ... 010 V1	10	62	52	0.06
AFH ... 012 V1	12.7	67.4	54.7	0.06
AFH ... 015 V1	15	72	57	0.06
AFH ... 019 V1	19	80	61	0.07
AFH ... 025 V1	25	92	67	0.07
AFH ... 038 V1	38	118	80	0.08
AFH ... 050 V1	50	142	92	0.09
AFH ... 063 V1	63.5	172	108.5	0.10
AFH ... 075 V1	75	195	120	0.11
AFH ... 080 V1	80	205	125	0.12

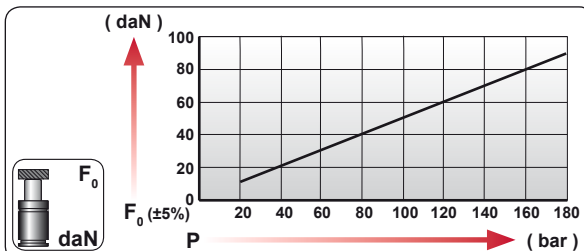


CODE	COLOR	Pressure		Force	
		bar	psi	daN	daN
AFH 18 050 V1	Green	35	510	18	35
AFH 35 050 V1	Blue	70	1015	35	70
AFH 50 050 V1	Red	100	1450	50	100
AFH 70 050 V1	Yellow	140	2030	70	140
AFH XX 050 V1	Black	20-180	290-2610	10 - 90	20 - 180

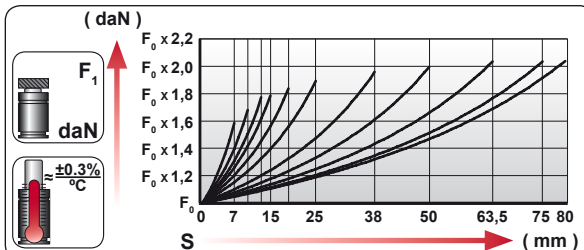

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

AFH 90 50

AFH 90 050 V1


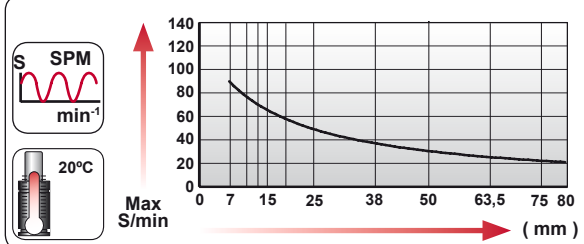


N ₂	S _{max} < 90%	V _{max} 1,6 m/s	P _{min} (20°C) P _{max} (20°C)	T _{min} T _{max}	








bar	psi	bar	psi	°C	°F	°C	°F	X
20	290	180	2610	0	32	80	176	

Mini

A14-015

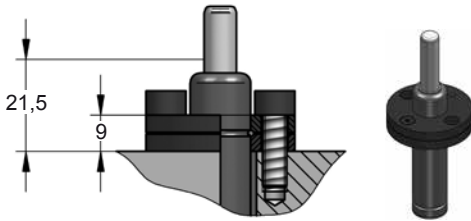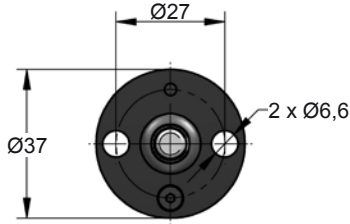

A49-015

  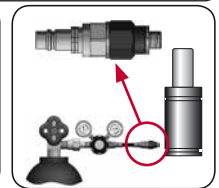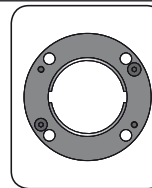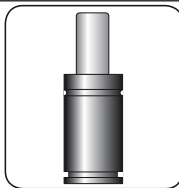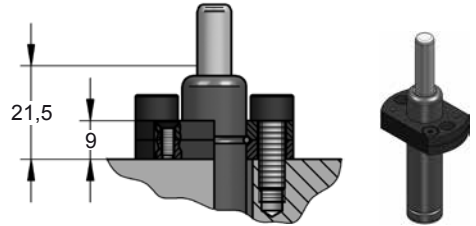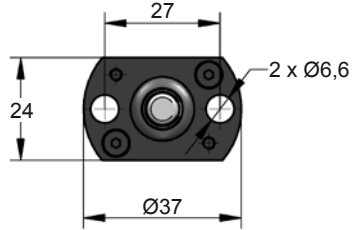

CODE	AFH 90 050 V1	X	A14-015	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA