


APFA 150

150



BMW B2 4006		PSA E24.54.815.G
MB B8 3180 220 000 001	GM 90.25	RENAULT EM24.54.700
VW 39D 878		

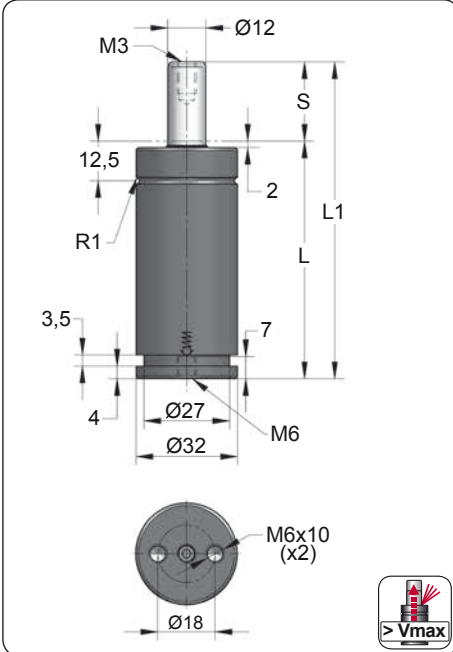

CODE	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
APFA ... 010	10	70	60	0.29
APFA ... 012	12.7	75.4	62.7	0.30
APFA ... 016	16	82	66	0.31
APFA ... 025	25	100	75	0.34
APFA ... 038	38	126	88	0.38
APFA ... 050	50	150	100	0.42
APFA ... 063	63.5	177	113.5	0.47
APFA ... 080	80	210	130	0.52
APFA ... 100	100	250	150	0.59
APFA ... 125	125	300	175	0.67




CODE	COLOR	Pressure		Force	
		bar	psi	daN	daN
APFA 50 050	Green	45	650	50	65
APFA 100 050	Blue	90	1305	100	130
APFA 150 050	Red	135	1960	150	195
APFA 200 050	Yellow	180	2610	200	260

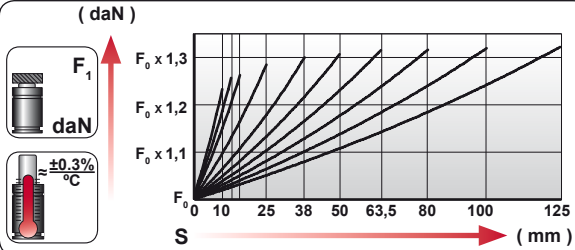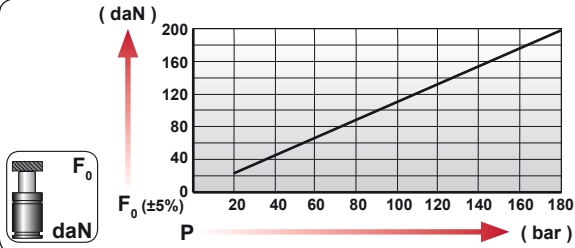

ENG	ORDER
DEU	BESTELLUNG
FRA	COMMANDE
ITA	ORDINE
ESP	PEDIDO
POR	PEDIDO

APFA 50 **50**

APFA 50 050

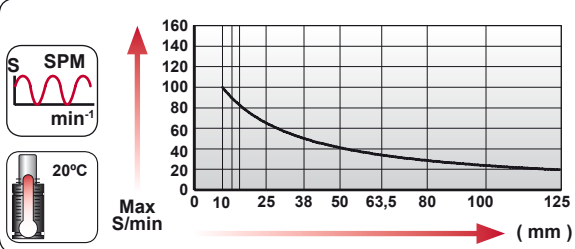

--	--	--	--	--	--



N ₂	Smax < 90%	Vmax 1,6 m/s	bar psi 20 290	bar psi 180 2610	°C °F 0 32	°C °F 80 176	
----------------	------------	--------------	-------------------	---------------------	---------------	-----------------	--





APFA 150 MOUNTS

150



A14-032

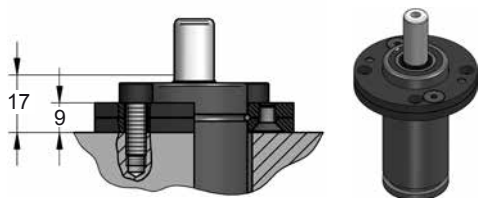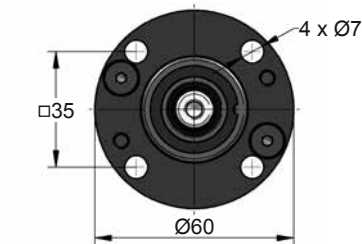





A34-032

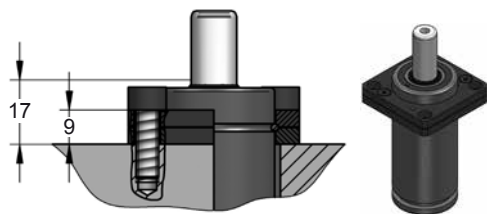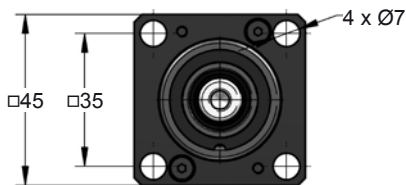

C20-032

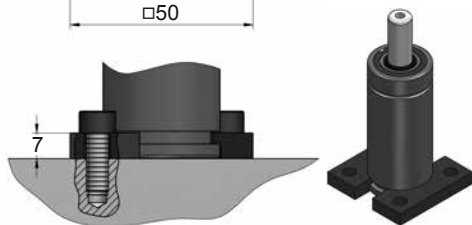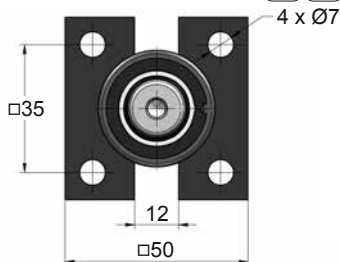

D02-032

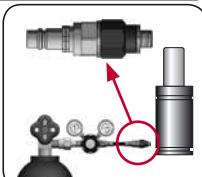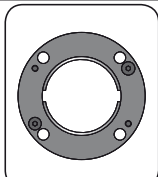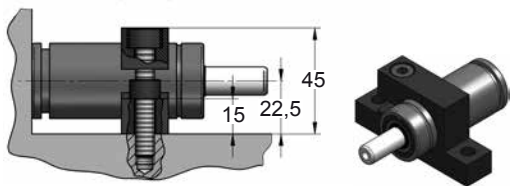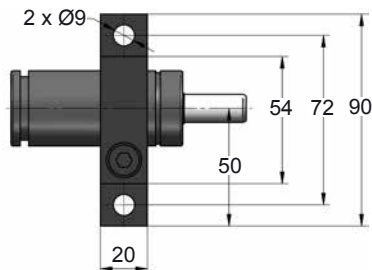

CODE	APFA 50 050	KIT S-XXXXXXX KIT C-XXXXXXX	A14-032	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCH	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GAS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA