




CW 6600

Compact Height




BMW B2 4005	FORD W-DX35-6204	
MB B8 3180 220 000 004		
VW 39D 997		

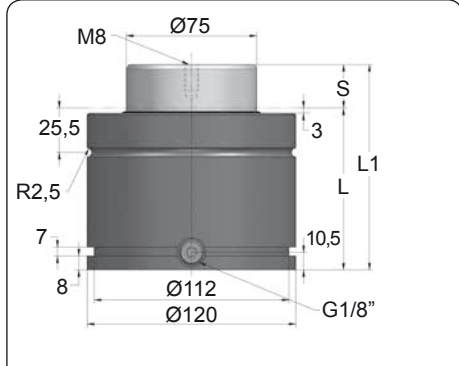

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CW 6600 016	16	100	84	5.55
CW 6600 019	19	106	87	5.69
CW 6600 025	25	118	93	5.97
CW 6600 032	32	132	100	6.29
CW 6600 038	38	144	106	6.57
CW 6600 050	50	168	118	7.13
CW 6600 063	63	194	131	7.73
CW 6600 075	75	218	143	8.29
CW 6600 080	80	228	148	8.52
CW 6600 100	100	268	168	9.45
CW 6600 125	125	318	193	10.61

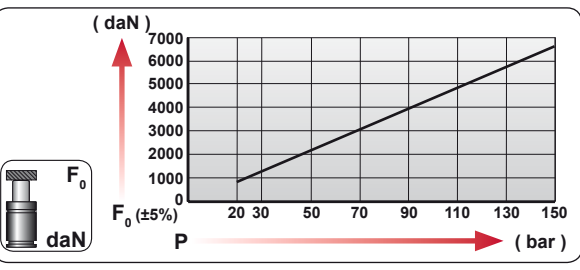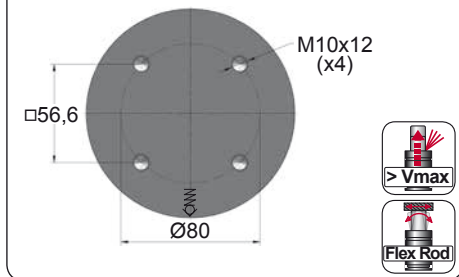

CODE	Pressure (bar/psi)	F ₀ (daN)	F ₁ (daN)
CW 6600 050	150 / 2175	6630	12380
CW-H 6600 050	0 / 0	---	---

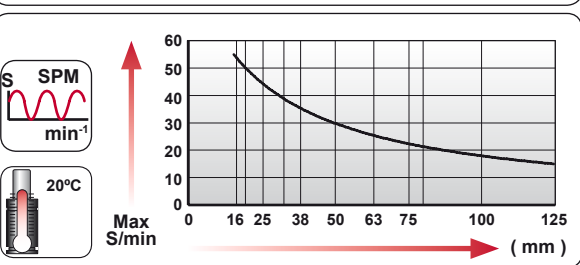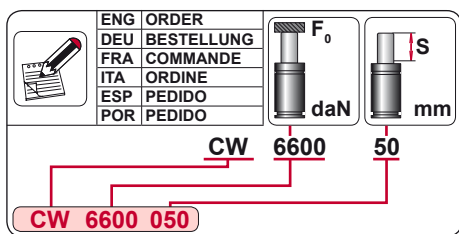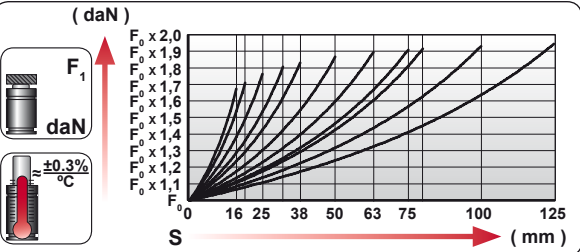

N₂

Smax < 90%

Vmax 1,6 m/s

Pmin (20°C) Pmax (20°C)

Tmin Tmax

600 CP-

N ₂	Smax < 90%	Vmax 1,6 m/s	bar psi	bar psi	°C °F	°C °F	600 CP-
			20 290	150 2175	0 32	80 176	


CW 6600 MOUNTS

Compact Height

	50 Ø120 L1=168 L1=172	50 Ø120 L1=190	50 Ø120 L1=202 L1=215 L1=240	50 Ø120 L1=240	50 Ø120 L1=260			
MODEL	×	CW 6600 KZ 6600	×	FD 5000	GN 5000 CM 6500 CD 6600	AG 5000	×	CS 11800
SERIES	MINI 	COMPACT HEIGHT 	THREADED 	LOW PROFILE 	HEAVY DUTY 	ISO 	HEAVY LOAD 	POWER COMPACT STROKE





A14-120

ISO VALVE TYP. E24.54.815.G EM24.54.700/F

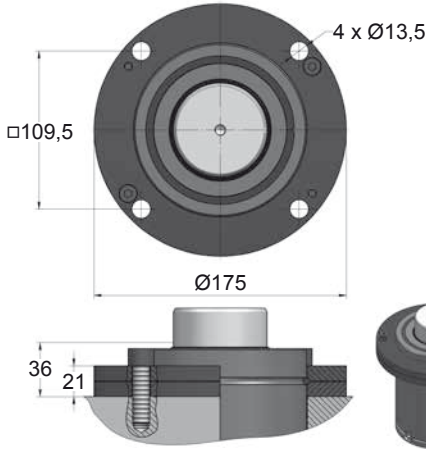

A34-120

ISO VDI

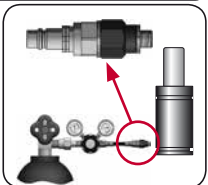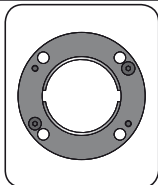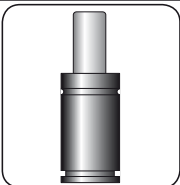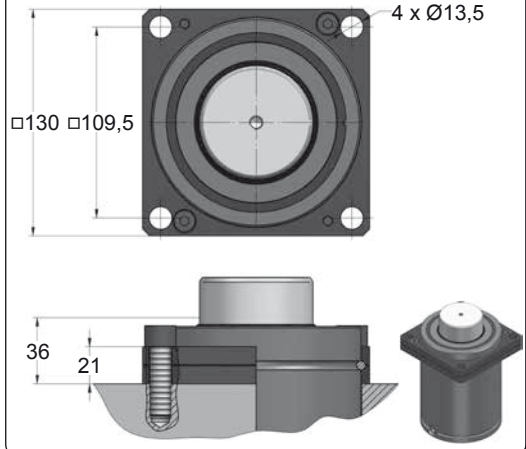



CODE	CW 6600 050	KIT S-XXXXXXX KIT C-XXXXXXX	A14-120	18 CG 1-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA

CW 6600 MOUNTS



Compact Height

AZOL
GAS



B36-120

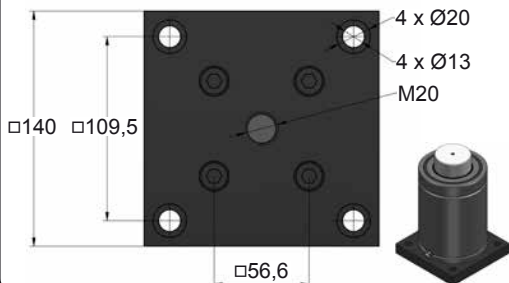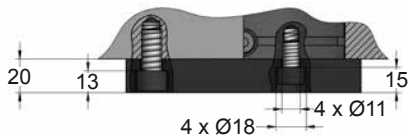






B41-120

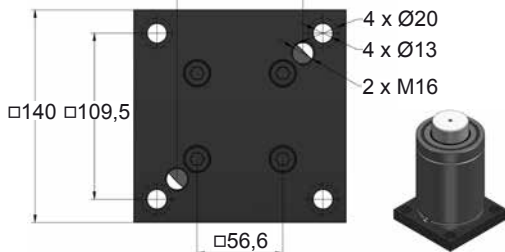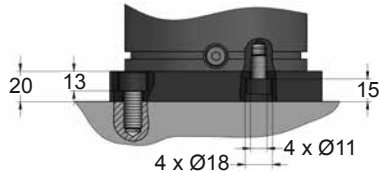

C05-120

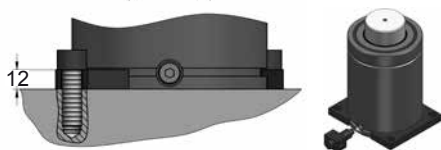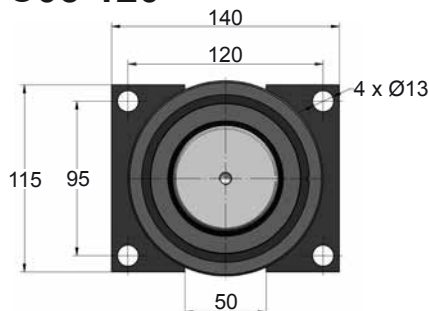

C20-120

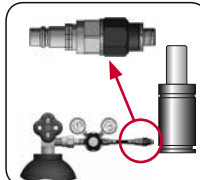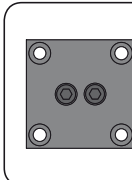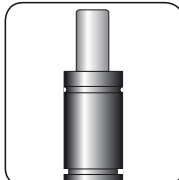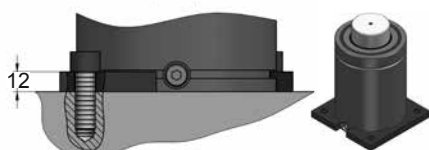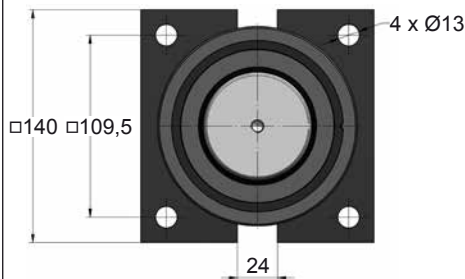


CODE	CW 6600 050	KIT S-XXXXXXX KIT C-XXXXXXX	B36-120	18 CG 1-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA

CW 6600 MOUNTS







Compact Height

D02-120

2 x Ø13,5

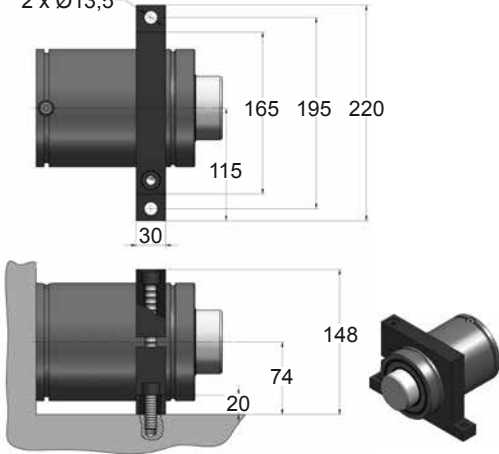

D67-120

  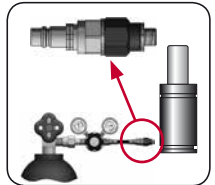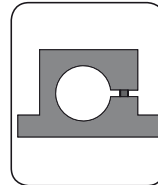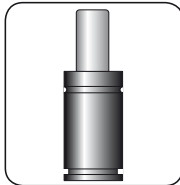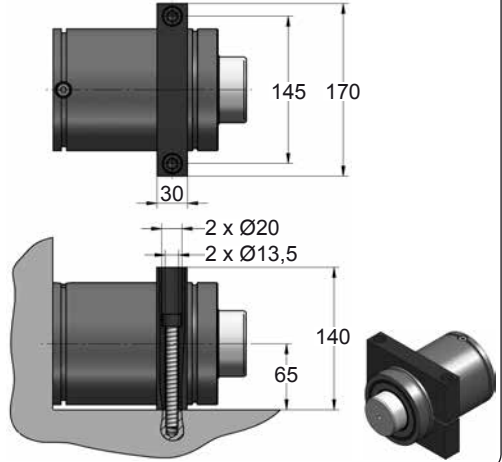

CODE	CW 6600 050	KIT S-XXXXXXX KIT C-XXXXXXX	D02-120	18 CG 1-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA