



CP 1000 V1


Heavy Load

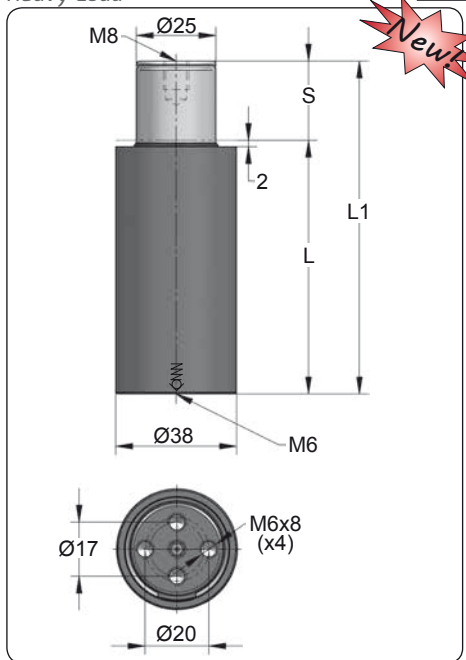


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CP 1000 010 V1	10	75	65	0.43
CP 1000 015 V1	15	85	70	0.45
CP 1000 025 V1	25	105	80	0.51
CP 1000 038 V1	38	135	97	0.58
CP 1000 050 V1	50	160	110	0.65
CP 1000 063 V1	63	205	142	0.77
CP 1000 080 V1	80	240	160	0.86

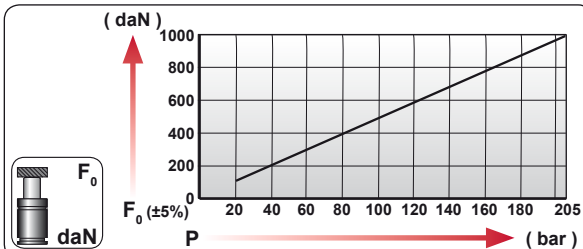

CODE				
	bar	psi	daN	daN
CP 1000 050 V1	195	2830	960	1655
-----	---	---	---	---

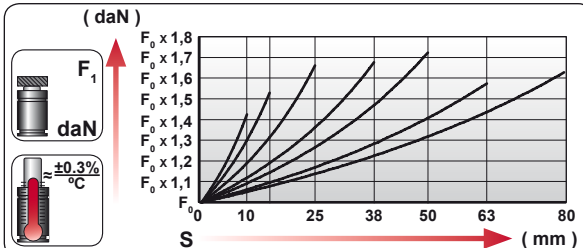

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO		
		daN	mm
		CP 1000	50
		CP 1000 050 V1	

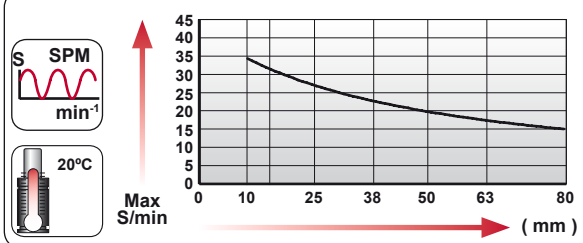







N ₂	S _{max} < 90%	V _{max} 0,5 m/s	P _{min} (20°C)	P _{max} (20°C)	T _{min}	T _{max}	

N ₂	S _{max} < 90%	V _{max} 0,5 m/s	bar psi	bar psi	°C °F	°C °F	°C °F	
			20 290	205 2975	0 32	80 176		

CP 1000 V1 MOUNTS

Heavy Load

MODEL	X	CW 500 KZ 500	AS 300	CT 550 CK 570	CM 500 CD 500	APFA 250	CPH 850 CP 1000	CS 1000
SERIES	MINI	COMPACT HEIGHT	THREADED	LOW PROFILE	HEAVY DUTY	ISO	HEAVY LOAD	POWER COMPACT STROKE

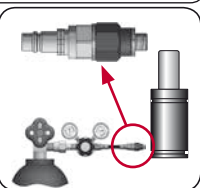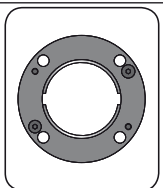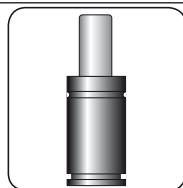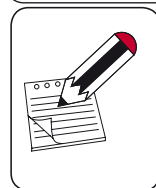  

CODE	CP 1000 050 V1	KIT S-XXXXXXX	X	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA