



CPH 1250 V1

Heavy Load




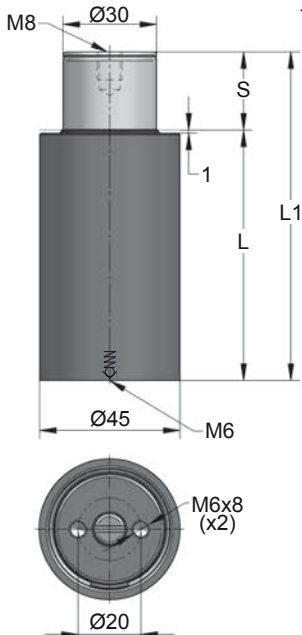


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CPH 1250 012 V1	12	79	67	0.61
CPH 1250 025 V1	25	105	80	0.73
CPH 1250 038 V1	38	135	97	0.81
CPH 1250 050 V1	50	160	110	0.98
CPH 1250 063 V1	63	190	127	1.12
CPH 1250 080 V1	80	230	150	1.25

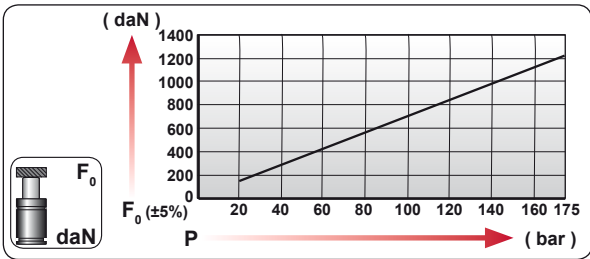

CODE					
		bar	psi		
CPH 1250 050 V1		170	2465	1200	2150
-----		---	---	---	---

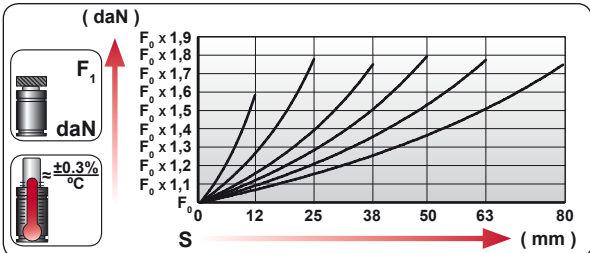

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO		
		daN	mm
		CPH 1250	50
		CPH 1250 050 V1	

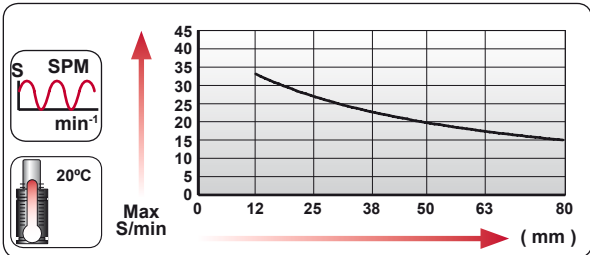

N ₂	S _{max} < 90%	V _{max} 0,5 m/s	P _{min} (20°C)	P _{max} (20°C)	T _{min}	T _{max}	







bar	psi	bar	psi	°C	°F	°C	°F	
20	290	175	2540	0	32	80	176	



CPH 1250 V1 MOUNTS

Heavy Load

	50	50	50	50	50	50	50	
	Ø45	Ø45	Ø45	Ø45	Ø45	Ø45	Ø45	
	L1=132	L1=132	L1=150	L1=160	L1=185	L1=185	L1=160	
	L1=147		L1=150	L1=185				
MODEL	×	CW 750 KZ 750	AS 700	CK 750 FD 500	CM 600 CD 700	APF 500	CPH 1250	×
SERIES	MINI	COMPACT HEIGHT	THREADED	LOW PROFILE	HEAVY DUTY	ISO	HEAVY LOAD	POWER COMPACT STROKE

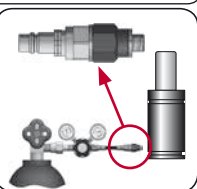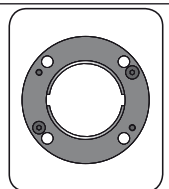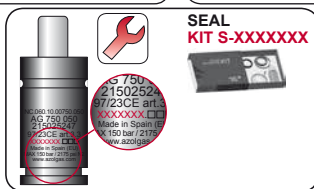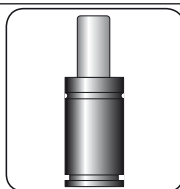  

CODE	CPH 1250 050 V1	KIT S-XXXXXXX	×	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GAS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA