



CPH 2800 V1

Heavy Load

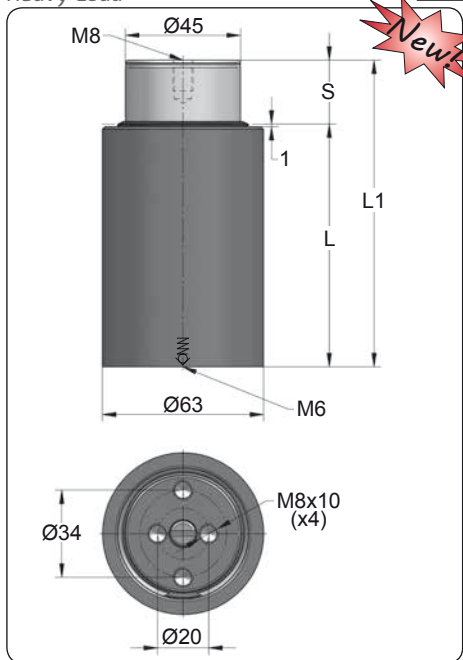





ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CPH 2800 012 V1	12	94	82	1.58
CPH 2800 025 V1	25	120	95	1.79
CPH 2800 038 V1	38	150	112	2.04
CPH 2800 050 V1	50	175	125	2.24
CPH 2800 063 V1	63	210	147	2.53
CPH 2800 080 V1	80	250	170	2.85

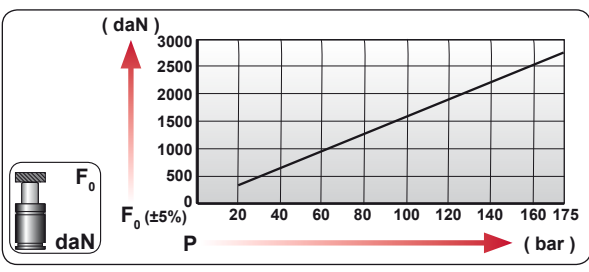

CODE					
		bar	psi		
CPH 2800 050 V1		170	2465	2700	5260
-----		---	---	---	---

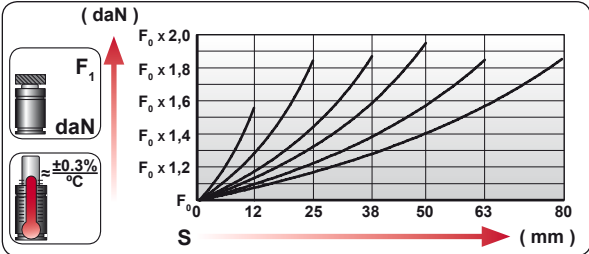

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO		
		daN	mm
		CPH 2800	50
		CPH 2800 050 V1	

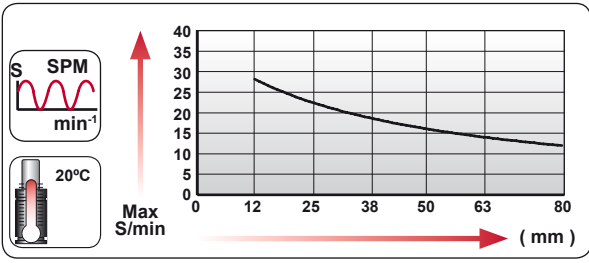

N ₂	S _{max} < 90%	V _{max} 0,5 m/s	P _{min} (20°C)	P _{max} (20°C)	T _{min}	T _{max}	






bar	psi	bar	psi	°C	°F	°C	°F	
20	290	175	2540	0	32	80	176	



CPH 2800 V1 MOUNTS

Heavy Load

 	 50 Ø63 L1=135 L1=144 L1=152	 50 Ø63 L1=152 L1=160	 50 Ø63 L1=185 L1=195	 50 Ø63 L1=175 L1=190	 50 Ø63 L1=205			
MODEL	✗	CR 1500 CW 1500 KZ 1500	✗	CT 1500 CK 1500	CM 1500 CD 1500	✗	CPH 2800 CP 3000	CS 3000
SERIES	MINI 	COMPACT HEIGHT 	THREADED 	LOW PROFILE 	HEAVY DUTY 	ISO 	HEAVY LOAD 	POWER COMPACT STROKE

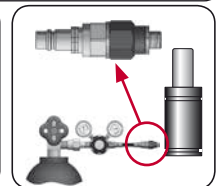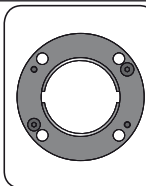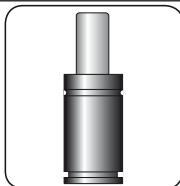  

CODE	CPH 2800 050 V1	KIT S-XXXXXXX	✗	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GAS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA