



# CPH 4300 V1

Heavy Load

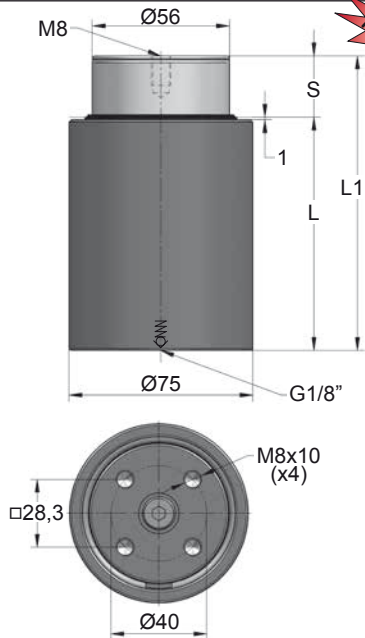


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CPH 4300 012 V1	12	94	82	2.26
CPH 4300 025 V1	25	120	95	2.54
CPH 4300 038 V1	38	150	112	2.87
CPH 4300 050 V1	50	175	125	3.14
CPH 4300 063 V1	63	210	147	3.52
CPH 4300 080 V1	80	250	170	3.96



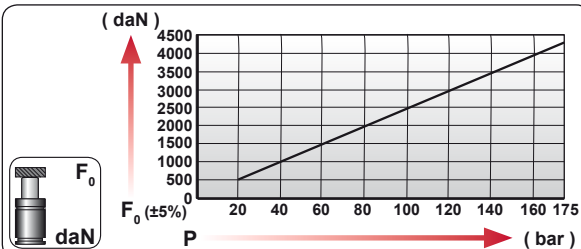
CODE					
		bar	psi		
CPH 4300 050 V1		170	2465	4190	8100
-----		-----	-----	-----	-----

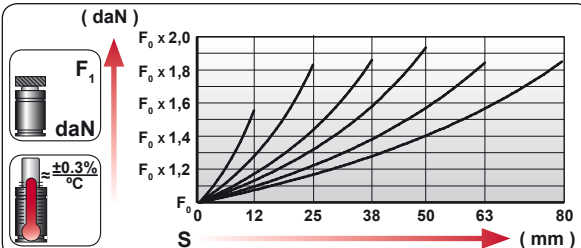

	ENG ORDER		
	DEU BESTELLUNG	daN	mm
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

CPH 4300 50

CPH 4300 050 V1

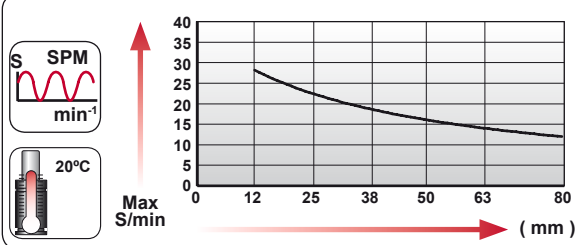





 
 
N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub>	T <sub>max</sub>	

bar	psi	bar	psi	°C	°F	°C	°F	<b>X</b>
20	290	175	2540	0	32	80	176	

# CPH 4300 V1 MOUNTS

Heavy Load

  	 <b>Ø75</b> L1=137 L1=145 L1=159	 <b>Ø75</b> L1=154 L1=160 L1=160	 <b>Ø75</b> L1=185 L1=195 L1=210	 <b>Ø75</b> L1=210	 <b>Ø75</b> L1=175 L1=200	 <b>Ø75</b> L1=240		
<b>MODEL</b>	<b>×</b> CR 2400 CW 2400 KZ 2400	<b>×</b>	CT 2500 CK 2500 FD 1500	GN 1500 CM 2500 CD 2400	AG 1500	<b>CPH 4300</b> <b>CP 5000</b>	CS 4700	
<b>SERIES</b>	<b>MINI</b> 	<b>COMPACT HEIGHT</b> 	<b>THREADED</b> 	<b>LOW PROFILE</b> 	<b>HEAVY DUTY</b> 	<b>ISO</b> 	<b>HEAVY LOAD</b> 	<b>POWER COMPACT STROKE</b> 

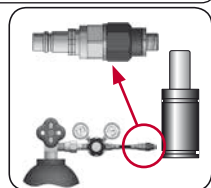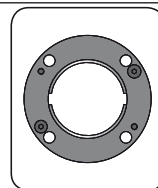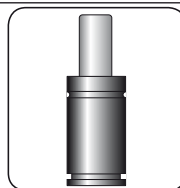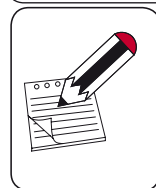

<b>CODE</b>	<b>CPH 4300 050 V1</b>	<b>KIT S-XXXXXXX</b>	<b>×</b>	<b>06 CG 2-Q</b>
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCH	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GAS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA