



AZOL GAS ROT 750


Special Applications

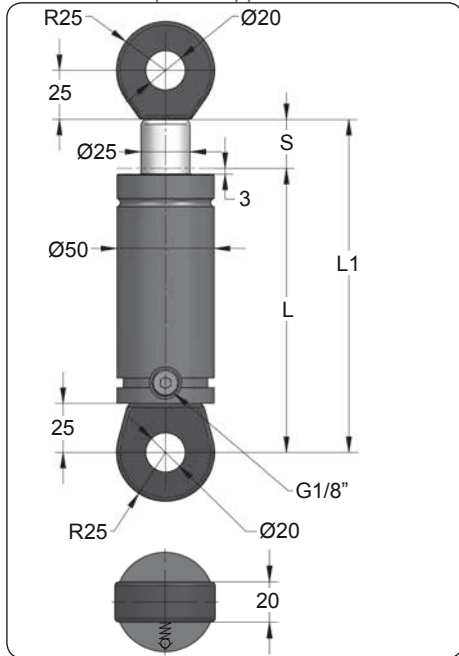

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ROT 750 012	12.7	145.4	132.7	1.74
ROT 750 025	25	170	145	1.96
ROT 750 038	38	196	158	2.04
ROT 750 050	50	220	170	2.14
ROT 750 063	63.5	247	183.5	2.24
ROT 750 080	80	280	200	2.44
ROT 750 100	100	320	220	2.68
ROT 750 125	125	370	245	2.84
ROT 750 160	160	440	280	3.12

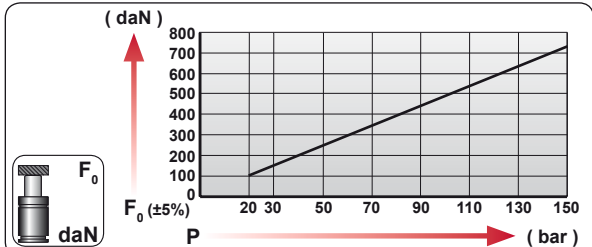

CODE		bar		psi			
		bar	psi	daN	daN		
ROT 750 050		150	2175	740	1100		
-----		---	---	---	---		

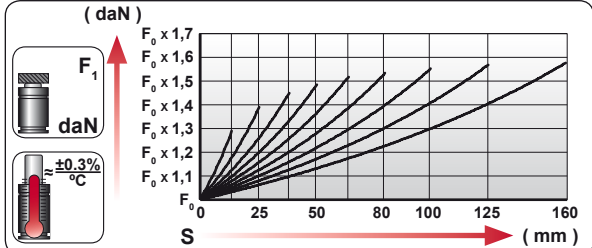

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

ROT 750 50

ROT 750 050

SEAL KIT S-XXXXXXX CARTRIDGE KIT C-XXXXXXX

KIT S-XXXXXXX
KIT C-XXXXXXX

18 CG 1-Q

ENG REPAIR KIT	CHARGING ADAPTER
DEU ERSATZ	LADEADAPTER
FRA KIT DE RÉPARATION	RACCORD DE CHARGE
ITA KIT DI MANUTENZIONE	ADATTATORE DI CARICO
ESP KIT DE REPARACION	ADAPTADOR DE CARGA
POR KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA

N ₂	Smax < 90%	Vmax 1,6 m/s	bar psi 20 290	bar psi 150 2175	°C °F 0 32	°C °F 80 176	600 CP-