


# Terminal Boxes

## ABS Range

### ABS terminal box | DABP

IP 66,67 | IK 06/07

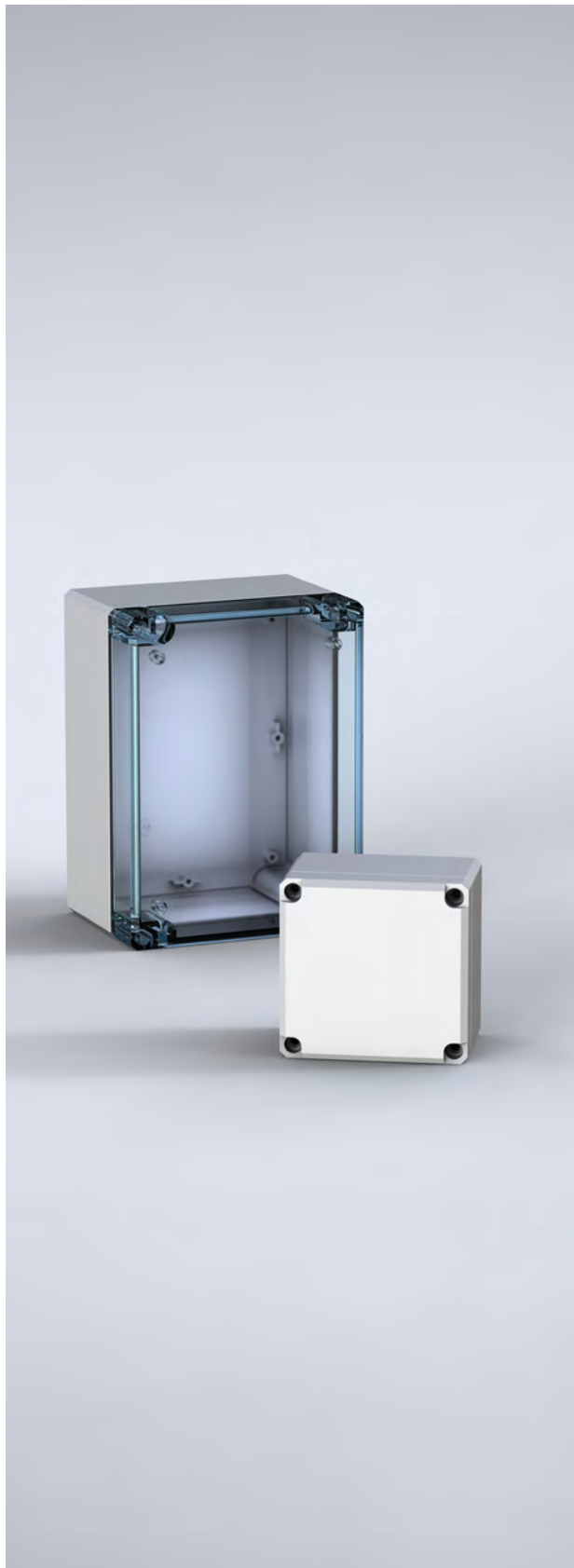

**Description:**

ABS box, halogen-free, suitable for indoor use.  
Low UV radiation resistance.

**Material:**

ABS.

**Gasket:**

Polyurethane gasket integrated in the box cover.

**Temperature resistance:**

-40°C to +60°C.

**Flammability:**

UL94 HB.

**Protection:**

IP 66, 67 | IK 06 (-25°C), IK 07 (+35°C).

**Finish:**

RAL 7035.

**Approvals:**

CE, GOST.

**Delivery:**

Body, cover, cover screws made from stainless steel,  
mounting screws and cover plugs made from polyamide.




IP 66,67 | IK 06/07





Box dimension				
H	W	D	Inner depth (mm)	Item no.
53	55	36	27.5	DABP050504GE
53	63	36	25	DABP050704GE
80	82	56	42	DABP080806GE
80	82	86	72	DABP080809GE
80	120	56	42	DABP081206GE
80	120	86	72	DABP081209GE
80	160	56	42	DABP081606GE
80	160	86	72	DABP081609GE
120	122	56	42	DABP121206GE
120	122	86	72	DABP121209GE
120	160	91	77	DABP121609GE
120	200	86	72	DABP122009GE
150	200	76	62	DABP152008GE
160	240	91	77	DABP162409GE
160	240	121	107	DABP162412GE
230	300	86	72	DABP233009GE
230	300	111	97	DABP233011GE

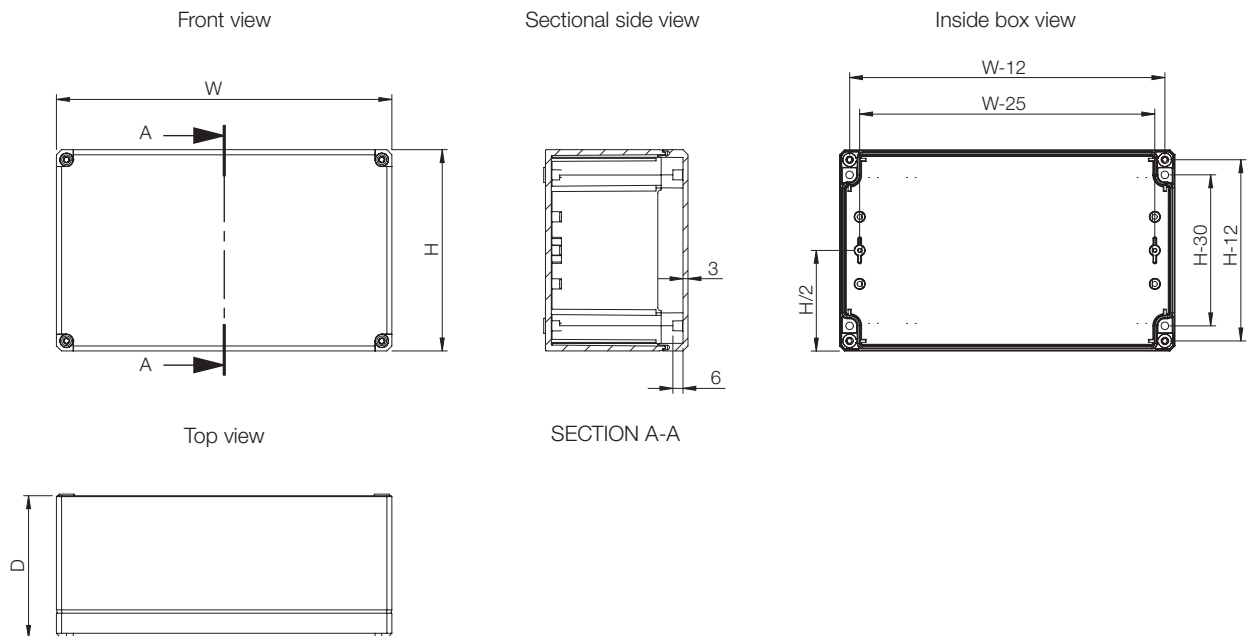Note: Terminal box with transparent cover fitted can be ordered by replacing GE with TE in the item number.

## Dimensional drawing | DABP



# Accessories selection matrix | DABP

							
Box				Mounting		Fixing	Cover
	H	W	D	Mounting plate	DIN rail	Wall mounting brackets	Hinges
DABP050504GE	53	55	36	-	-	DFL1E	DSH1E
DABP050704GE	53	63	36	-	-	DFL1E	DSH1E
DABP080806GE	80	82	56	DMP0808E	DR350584E	DFL1E	DSH1E
DABP080809GE	80	82	86	DMP0808E	DR350584E	DFL1E	DSH1E
DABP081206GE	80	120	56	DMP0812E	DR350964E	DFL1E	DSH1E
DABP081209GE	80	120	86	DMP0812E	DR350964E	DFL1E	DSH1E
DABP081606GE	80	160	56	DMP0816E	DR351364E	DFL1E	DSH1E
DABP081609GE	80	160	86	DMP0816E	DR351364E	DFL1E	DSH1E
DABP121206GE	120	122	56	DMP1212E	DR350964E	DFL1E	DSH1E
DABP121209GE	120	122	86	DMP1212E	DR350964E	DFL1E	DSH1E
DABP121609GE	120	160	91	DMP1216E	DR351364E	DFL1E	DSH1E
DABP122009GE	120	200	86	DMP1220E	DR351764E	DFL1E	DSH1E
DABP152008GE	150	200	76	DMP1520E	DR351604E	DFL1E	DSH1E
DABP162409GE	160	240	91	DMP1624E	DR352154E	DFL1E	DSH1E
DABP162412GE	160	240	121	DMP1624E	DR352154E	DFL1E	DSH1E
DABP233009GE	230	300	86	DMP2330E	DR352754E	DFL1E	DSH1E
DABP233011GE	230	300	111	DMP2330E	DR352754E	DFL1E	DSH1E