


# TORNILLO DE AJUSTE TUERCA HEXAGONAL DIN 6330 B

2140.02.

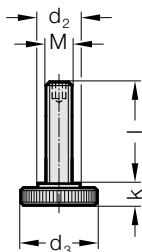


2140.02. Tornillo de ajuste

Código	M	d <sub>2</sub>	d <sub>3</sub>	k	l
2140.02.10	10	16	30	8	39
2140.02.12	12	20	36	10	48
2140.02.16	16	25	42	13	55
2140.02.20	20	25	50	16	69
2140.02.24	24	34	60	20	87

**Material:**

bonificado, categoría de resistencia 8.8

2140.32.

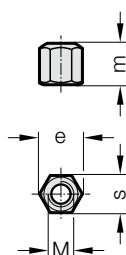

2140.32. Tuerca hexagonal DIN 6330 B

Código	M	e	m	s
2140.32.08	M8	15	12	13
2140.32.10	M10	18,4	15	16
2140.32.12	M12	20,7	18	18
2140.32.14	M14	24,2	21	21
2140.32.16	M16	27,7	24	24
2140.32.18	M18	31,2	27	27
2140.32.20	M20	34,6	30	30
2140.32.22	M22	39,2	33	34
2140.32.24	M24	41,5	36	36
2140.32.30	M30	53,1	45	46

**Material:**

bonificado, categoría de resistencia 10.9

**Nota:**

Usar arandelas según DIN 6340.