


# ŠROUBY PRO T DRÁŽKY, DIN 787

2140.30.

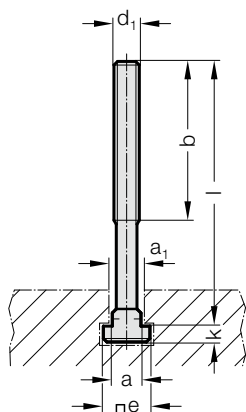

## Materiál:

zušlechtěný,

M 8 - M12 auf pevnostní třída 10.9

M14 - M30 auf pevnostní třída 8.8

## Provedení:

kovaný, Gewinde gerollt, vedení drážky T frézované

## 2140.30. Šrouby pro T drážky, DIN 787

| Objednací číslo   | a <sub>1</sub> | a    | b   | d <sub>1</sub> | e  | k  | l   |
|-------------------|----------------|------|-----|----------------|----|----|-----|
| 2140.30.08.08.032 | 8              | 7,7  | 22  | 8              | 13 | 6  | 32  |
| 2140.30.08.08.050 | 8              | 7,7  | 35  | 8              | 13 | 6  | 50  |
| 2140.30.08.08.080 | 8              | 7,7  | 50  | 8              | 13 | 6  | 80  |
| 2140.30.10.10.040 | 10             | 9,7  | 30  | 10             | 15 | 6  | 40  |
| 2140.30.10.10.063 | 10             | 9,7  | 45  | 10             | 15 | 6  | 63  |
| 2140.30.10.10.100 | 10             | 9,7  | 60  | 10             | 15 | 6  | 100 |
| 2140.30.12.12.050 | 12             | 11,7 | 35  | 12             | 18 | 7  | 50  |
| 2140.30.12.12.063 | 12             | 11,7 | 40  | 12             | 18 | 7  | 63  |
| 2140.30.12.12.080 | 12             | 11,7 | 55  | 12             | 18 | 7  | 80  |
| 2140.30.12.12.125 | 12             | 11,7 | 75  | 12             | 18 | 7  | 125 |
| 2140.30.12.12.200 | 12             | 11,7 | 120 | 12             | 18 | 7  | 200 |
| 2140.30.12.14.050 | 14             | 13,7 | 35  | 12             | 22 | 8  | 50  |
| 2140.30.12.14.063 | 14             | 13,7 | 45  | 12             | 22 | 8  | 63  |
| 2140.30.12.14.080 | 14             | 13,7 | 55  | 12             | 22 | 8  | 80  |
| 2140.30.12.14.125 | 14             | 13,7 | 75  | 12             | 22 | 8  | 125 |
| 2140.30.12.14.200 | 14             | 13,7 | 120 | 12             | 22 | 8  | 200 |
| 2140.30.14.16.063 | 16             | 15,7 | 45  | 14             | 25 | 9  | 63  |
| 2140.30.14.16.100 | 16             | 15,7 | 65  | 14             | 25 | 9  | 100 |
| 2140.30.14.16.160 | 16             | 15,7 | 125 | 14             | 25 | 9  | 160 |
| 2140.30.14.16.250 | 16             | 15,7 | 150 | 14             | 25 | 9  | 250 |
| 2140.30.16.16.063 | 16             | 15,7 | 45  | 16             | 25 | 9  | 63  |
| 2140.30.16.16.080 | 16             | 15,7 | 55  | 16             | 25 | 9  | 80  |
| 2140.30.16.16.100 | 16             | 15,7 | 65  | 16             | 25 | 9  | 100 |
| 2140.30.16.16.160 | 16             | 15,7 | 100 | 16             | 25 | 9  | 160 |
| 2140.30.16.16.200 | 16             | 15,7 | 125 | 16             | 25 | 9  | 200 |
| 2140.30.16.16.250 | 16             | 15,7 | 150 | 16             | 25 | 9  | 250 |
| 2140.30.16.18.063 | 18             | 17,7 | 45  | 16             | 28 | 10 | 63  |
| 2140.30.16.18.080 | 18             | 17,7 | 55  | 16             | 28 | 10 | 80  |
| 2140.30.16.18.100 | 18             | 17,7 | 65  | 16             | 28 | 10 | 100 |
| 2140.30.16.18.160 | 18             | 17,7 | 100 | 16             | 28 | 10 | 160 |
| 2140.30.16.18.200 | 18             | 17,7 | 125 | 16             | 28 | 10 | 200 |
| 2140.30.16.18.250 | 18             | 17,7 | 150 | 16             | 28 | 10 | 250 |
| 2140.30.20.20.080 | 20             | 19,7 | 55  | 20             | 32 | 12 | 80  |
| 2140.30.20.20.100 | 20             | 19,7 | 65  | 20             | 32 | 12 | 100 |

| Objednací číslo   | a <sub>1</sub> | a    | b   | d <sub>1</sub> | e  | k  | l   |
|-------------------|----------------|------|-----|----------------|----|----|-----|
| 2140.30.20.20.125 | 20             | 19,7 | 85  | 20             | 32 | 12 | 125 |
| 2140.30.20.20.160 | 20             | 19,7 | 110 | 20             | 32 | 12 | 160 |
| 2140.30.20.20.200 | 20             | 19,7 | 125 | 20             | 32 | 12 | 200 |
| 2140.30.20.20.250 | 20             | 19,7 | 150 | 20             | 32 | 12 | 250 |
| 2140.30.20.20.315 | 20             | 19,7 | 190 | 20             | 32 | 12 | 315 |
| 2140.30.20.22.080 | 22             | 21,7 | 55  | 20             | 35 | 14 | 80  |
| 2140.30.20.22.100 | 22             | 21,7 | 65  | 20             | 35 | 14 | 100 |
| 2140.30.20.22.125 | 22             | 21,7 | 85  | 20             | 35 | 14 | 125 |
| 2140.30.20.22.160 | 22             | 21,7 | 110 | 20             | 35 | 14 | 160 |
| 2140.30.20.22.200 | 22             | 21,7 | 125 | 20             | 35 | 14 | 200 |
| 2140.30.20.22.250 | 22             | 21,7 | 150 | 20             | 35 | 14 | 250 |
| 2140.30.20.22.315 | 22             | 21,7 | 190 | 20             | 35 | 14 | 315 |
| 2140.30.24.24.100 | 24             | 23,7 | 70  | 24             | 40 | 16 | 100 |
| 2140.30.24.24.125 | 24             | 23,7 | 85  | 24             | 40 | 16 | 125 |
| 2140.30.24.24.160 | 24             | 23,7 | 110 | 24             | 40 | 16 | 160 |
| 2140.30.24.24.200 | 24             | 23,7 | 125 | 24             | 40 | 16 | 200 |
| 2140.30.24.24.250 | 24             | 23,7 | 150 | 24             | 40 | 16 | 250 |
| 2140.30.24.24.315 | 24             | 23,7 | 190 | 24             | 40 | 16 | 315 |
| 2140.30.24.24.400 | 24             | 23,7 | 240 | 24             | 40 | 16 | 400 |
| 2140.30.24.28.100 | 28             | 27,7 | 70  | 24             | 44 | 18 | 100 |
| 2140.30.24.28.125 | 28             | 27,7 | 85  | 24             | 44 | 18 | 125 |
| 2140.30.24.28.160 | 28             | 27,7 | 110 | 24             | 44 | 18 | 160 |
| 2140.30.24.28.200 | 28             | 27,7 | 125 | 24             | 44 | 18 | 200 |
| 2140.30.24.28.250 | 28             | 27,7 | 150 | 24             | 44 | 18 | 250 |
| 2140.30.24.28.315 | 28             | 27,7 | 190 | 24             | 44 | 18 | 315 |
| 2140.30.24.28.400 | 28             | 27,7 | 240 | 24             | 44 | 18 | 400 |
| 2140.30.30.36.125 | 36             | 35,6 | 80  | 30             | 54 | 22 | 125 |
| 2140.30.30.36.160 | 36             | 35,6 | 110 | 30             | 54 | 22 | 160 |
| 2140.30.30.36.200 | 36             | 35,6 | 135 | 30             | 54 | 22 | 200 |
| 2140.30.30.36.250 | 36             | 35,6 | 150 | 30             | 54 | 22 | 250 |
| 2140.30.30.36.315 | 36             | 35,6 | 200 | 30             | 54 | 22 | 315 |
| 2140.30.30.36.500 | 36             | 35,6 | 300 | 30             | 54 | 22 | 500 |