


# 电动输送带

## 2195.302.

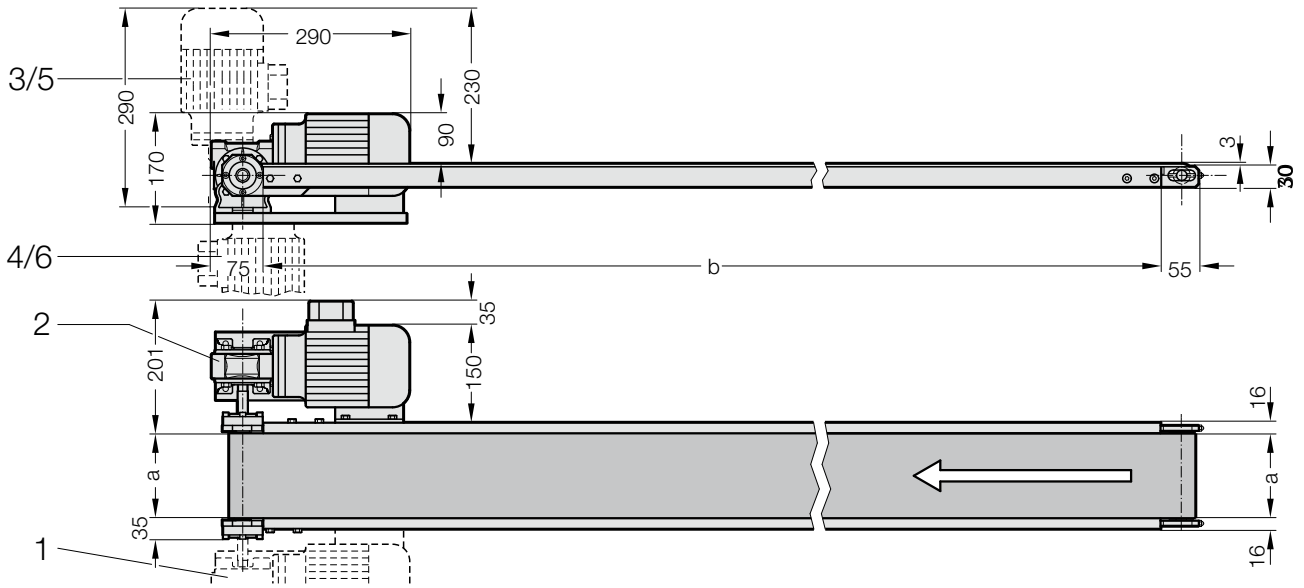

2195.302. 电动输送带

b	1,000	1,250	1,500	1,750	2,000	2,250	2,500	2,750	3,000	3,250	3,500	3,750	4,000
a													
30								●	●	●	●	●	●
50								●	●	●	●	●	●
75						●	●	●	●	●	●	●	●
100						●	●	●	●	●	●	●	●
125				●	●	●	●	●	●	●	●	●	●
150				●	●	●	●	●	●	●	●	●	●
175			●	●	●	●	●	●	●	●	●	●	●
200			●	●	●	●	●	●	●	●	●	●	●
225		●	●	●	●	●	●	●	●	●	●	●	●
250		●	●	●	●	●	●	●	●	●	●	●	●
275	●	●	●	●	●	●	●	●	●	●	●	●	●
300	●	●	●	●	●	●	●	●	●	●	●	●	●

### 带负载:

带宽 a	千克每延米
30-50-75	4
100-125-150	7
175-200-225	10
250-275-300	15

更多信息, 请参见说明书和订购指南。

### 订购示例:

电动输送带	= 2195.
型号 302	= 302.
带宽 a = 100 mm	= 100.
额定带长 b = 2500 mm	= 2500.
输送带速度	= 1
电机 400 v	= 3
电机位置	= 1
电机控制装置	= 1
订购号	= 2195.302. 100. 2500.1 3 1 1