



# TAŞIYICI ELEKTROMEKANİK, YATAY MERKEZ ŞANZIMAN POZİSYONU, 2 KIZAK, PROFILLİ VE DESTEKLI

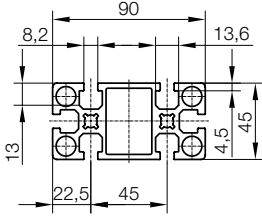

2299.222.

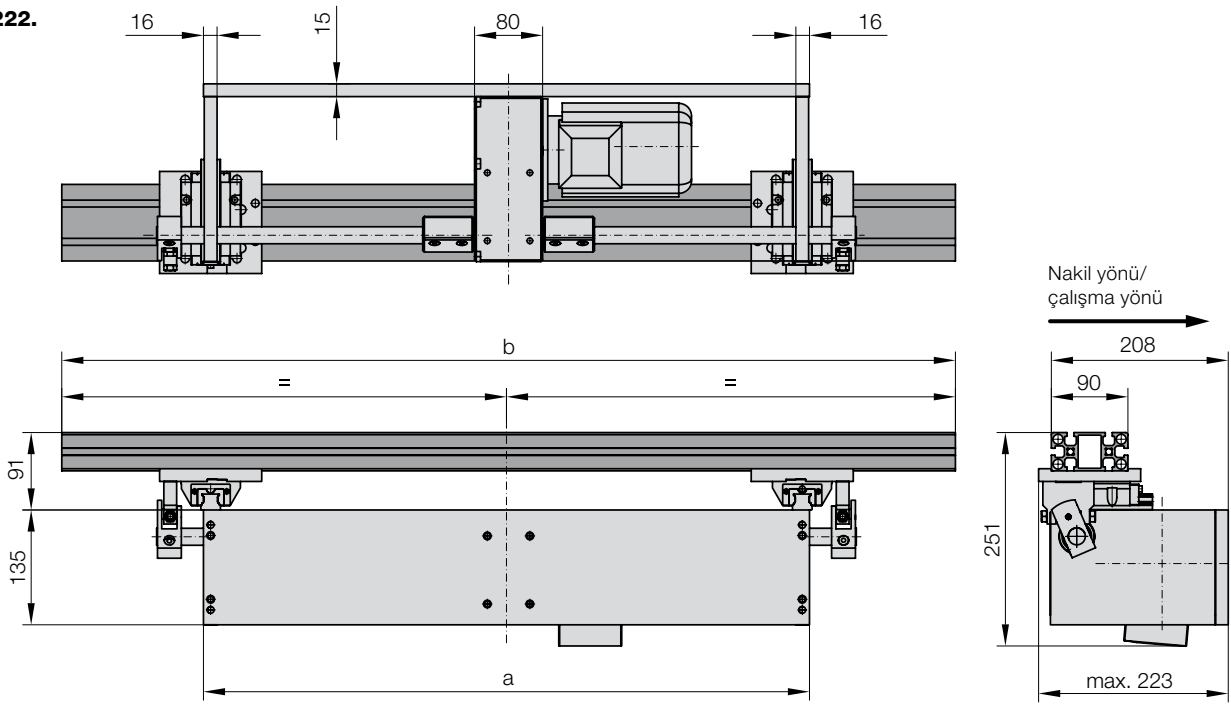

2299.222. Taşıyıcı elektromekanik, yatay merkez şanzıman pozisyonu, 2 kızak, profilli ve destekli

b	3.100	3.200	3.300	3.400	3.500	3.600	3.700	3.800	3.900	4.000	4.100	4.200	4.300	4.400	4.500	4.600	4.700	4.800	4.900	5.000	
a																					
1720	•	•	•	•	•	•															
2320							•	•	•	•	•	•	•	•	•	•	•	•	•	•	•
2920															•	•	•	•	•	•	•

## Siparis Kodu (örnek):

Taşıyıcı elektromekanik, yatay merkez şanzıman pozisyonu,  
2 kızak, profilli ve destekli

= 2299.222.  
b = 3800 mm = 3800.  
a = 2320 mm = 2320  
Siparis No = 2299.222.3800.2320