



ELASTOMER YAYLAR İÇİN DİŞLİ DİSK HELİS YAYLAR DİŞ AÇILMIŞ DİSK

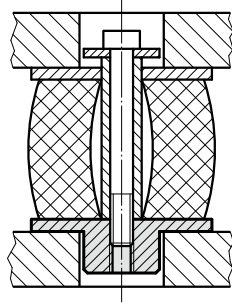

Montaj Örneği



2441.14.

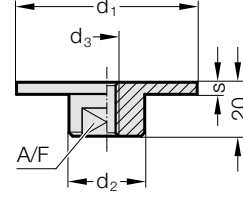

Malzeme:

St 60

2441.14. Elastomer yaylar için dişli disk


Yay ø	25	32	40	50	63	80	100
d ₁	32	40	50	60	78	98	120
d ₂	18	18	18	20	20	26	26
d ₃	M6	M8	M8	M10	M10	M12	M12
SW	14	14	14	17	17	22	22
s	5	5	5	6	8	10	12

Siparis Kodu (örnek):


Elastomer yaylar için dişli disk	=	2441.14.
Yay çapı Yay Ø	50 mm =	050
Siparis No	=	2441.14. 050



Montaj Örneği

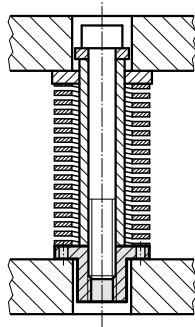

2441.15.

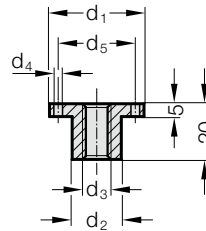

Malzeme:

Çk 45 baskı işlemli

2441.15. Helis yaylar diş açılmış disk

Yay-ø d ₁	d ₂	d ₃	d ₄	d ₅
20	10	M6	3,2	14
25	12,5	M8	4,2	20
32	16	M10	4,2	25
40	20	M12	4,2	30
50	25	M16	4,2	40

Siparis Kodu (örnek):

Helis yaylar diş açılmış disk	=	2441.15.
Yay çapı Yay Ø d ₁	32 mm =	032
Siparis No	=	2441.15. 032