



间隔管

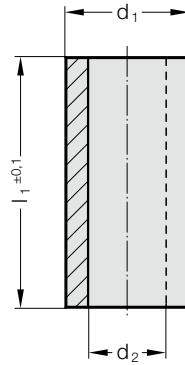

244.9.



安装示例

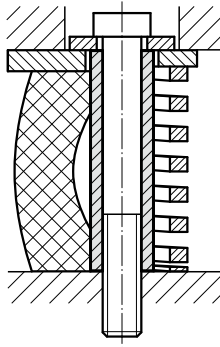

244.9. 间隔管

d ₁	10	12	13	16	19	20	25	30	32	35	36	36	42	42	55	
d ₂	6.4	8.4	9	11	13	13	17	22	22	23	22	26	26	32	31	
l ₁																
27	•	•														
30																
33	•	•														
38	•	•														
40																
44	•	•														
48	•	•														
50																
61	•	•														
63																
70																
72	•	•														
80	•	•														
90																
95																
100																
105																
115																
125																
135																
145																
150																
155																
165																
175																
185																
195																
200																
205																
215																
225																
235																
245																
250																
255																

材料:
E235 (1.0308), 碳氮共渗
说明:
其它长度请向我公司咨询!

订购示例:

间隔管	=	244.9.
内径 d ₂	6,4 mm	= 064.
外径 d ₁	10 mm	= 10.
长度 l ₁	27 mm	= 027
订购编号	=	244.9. 064. 10. 027