
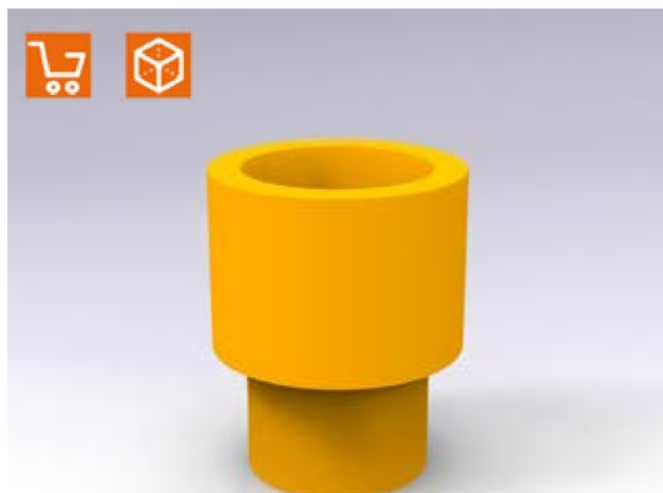


SPACER FOR DIE RELEASE

2533.10.

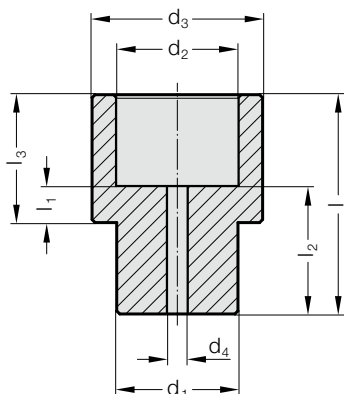


Description:

The spacers are inserted into the die for storage and transport purposes.

Material:

Greenamid PA6 (GF30), colour: yellow

Mounting example

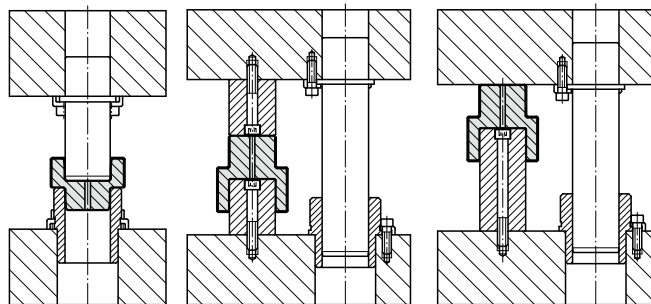

2533.10. Spacer for die release

Order No	d ₂	d ₁	l	l ₁	l ₂	l ₃	d ₃	d ₄ *	max. carrying capacity [daN]
2533.10.015	15.2	14.8	52	12	32	32	25	7	850
2533.10.016	16.2	15.8	52	12	32	32	26	7	850
2533.10.018	18.2	17.8	52	12	32	32	29	7	1,800
2533.10.019	19.2	18.8	52	12	32	32	30	7	1,800
2533.10.020	20.2	19.8	52	12	32	32	31	7	1,800
2533.10.024	24.2	23.8	56	12	34	34	36	7	3,400
2533.10.025	25.2	24.8	56	12	34	34	37	7	3,400
2533.10.030	30.2	29.8	60	12	36	36	44	7	3,500
2533.10.032	32.2	31.8	60	12	36	36	46	7	3,500
2533.10.038	38.2	37.8	73	12	43	43	54	7	5,500
2533.10.040	40.2	39.8	73	12	43	43	56	7	5,500
2533.10.042	42.2	41.8	73	12	43	43	58	7	5,500
2533.10.048	48.2	47.8	84	12	48	49	66	8.6	6,500
2533.10.050	50.2	49.8	84	12	48	49	68	8.6	6,500
2533.10.052	52.2	51.8	84	12	48	49	70	8.6	6,500
2533.10.060	60.2	59.8	92	12	52	53	79	8.6	10,000
2533.10.063	63.2	62.8	92	12	52	53	82	8.6	10,000
2533.10.080	80.2	79.8	94	14	54	54	102	8.6	15,000
2533.10.100	100.2	99.8	96	16	56	56	123	8.6	15,000
2533.10.125	125.2	124.8	96	16	56	56	150	8.6	15,000

*Tap hole for thread, created by customer