


SCHNELLWECHSEL-SCHNEIDSTEMPEL, ROHLING, MIT ABRÜCKSTIFT, SCHWER BELASTBAR

2703.

 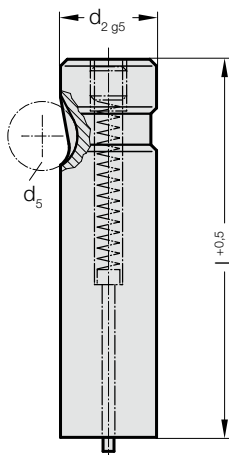


2703. Schnellwechsel-Schneidstempel, Rohling, mit Abdrückstift, schwer belastbar

d ₂ / (Bestellziffer)	d ₅	l / Bestellbuchstabe	63 (C)	71 (D)	80 (E)	90 (F)	100 (G)	110 (H)	125 (J)
10 / (2)	10		●	●	●	●	●		
13 / (3)	12		●	●	●	●		●	●
16 / (4)	12		●	●	●	●	●	●	●
20 / (5)	12		●	●	●	●	●	●	●
25 / (6)	12			●	●	●	●	●	●
32 / (7)	12			●	●	●	●	●	●
40 / (9)	12				●	●	●	●	●

Bestell-Beispiel:

2703.7G



Länge: l
100 mm
Durchmesser: d₂
32 mm
Typ:
schwer
Ausführung:
Rohling
Schneidstempel:
mit Abdrückstift

Bestellbuchstabe
= (G)
Bestellziffer
= (7)
Bestellziffer
= (3)
Bestellziffer
= (0)
= 27

Werkstoff:

HSS
Härte 62 ± 2 HRC

Ausführung:

Schaft feinstgeschliffen.
Sonderanfertigung auf Anfrage.