


BALL-LOCK PUNCH, STEPPED, ROUND, WITH EJECTOR PIN, LIGHT DUTY

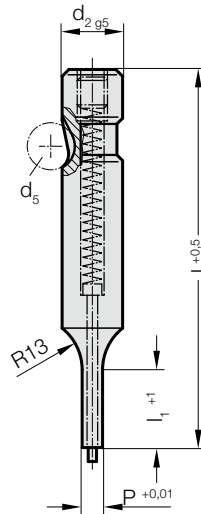

2712.



2712. Ball-Lock punch, stepped, round, with ejector pin, light duty

d ₂ / Order No	d _s	P	l ₁ / Order No	l (Order Code character)	63 (C)	71 (D)	80 (E)	90 (F)	100 (G)
6 / (1)	6	2,5 - 5,9	13(1)		●	●	●	●	●
10 / (2)	8	5 - 9,9	13(1) 19(2)		●	●	●	●	●
13 / (3)	8	6 - 12,9	13(1) 19(2)		●	●	●	●	●
16 / (4)	8	8 - 15,9	13(1) 19(2) 25(3)		●	●	●	●	●
20 / (5)	8	10 - 19,9	13(1) 19(2) 25(3)		●	●	●	●	●
25 / (6)	8	12 - 24,9	13(1) 19(2) 25(3)		●	●	●	●	●
32 / (7)	8	16 - 31,9	13(1) 19(2) 25(3)			●	●	●	●
38 / (8)	8	19 - 37,9	19(2) 25(3) 30(4)				●	●	●

Material:


HSS
Hardness 62 ± 2 HRC

Execution:

Shaft and punch diameter fine ground.
Special dimensions on request.

Ordering Code (example):

2712.7G2.2450

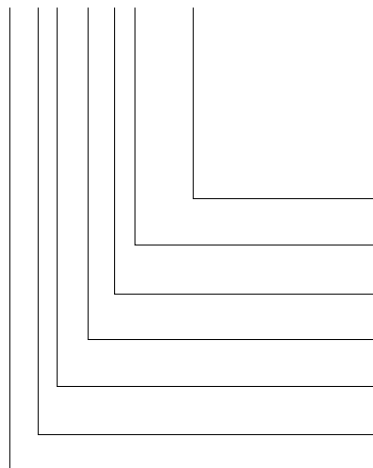

Shape: round

P = Ø 24,5 mm

Punch cutting length: l₁
19 mm

Length: l

100 mm

Diameter: d₂

32 mm

Type:

light

Execution:

round

Punch:

with ejector pin

= 2450

Order No

= (2)

Order Code character

= (G)

Order No

= (7)

Order No

= (2)

Order No

= (1)

= 27