


# SLIDING PAD, STEEL WITH OIL GROOVE, CNOMO



2960.44.45.

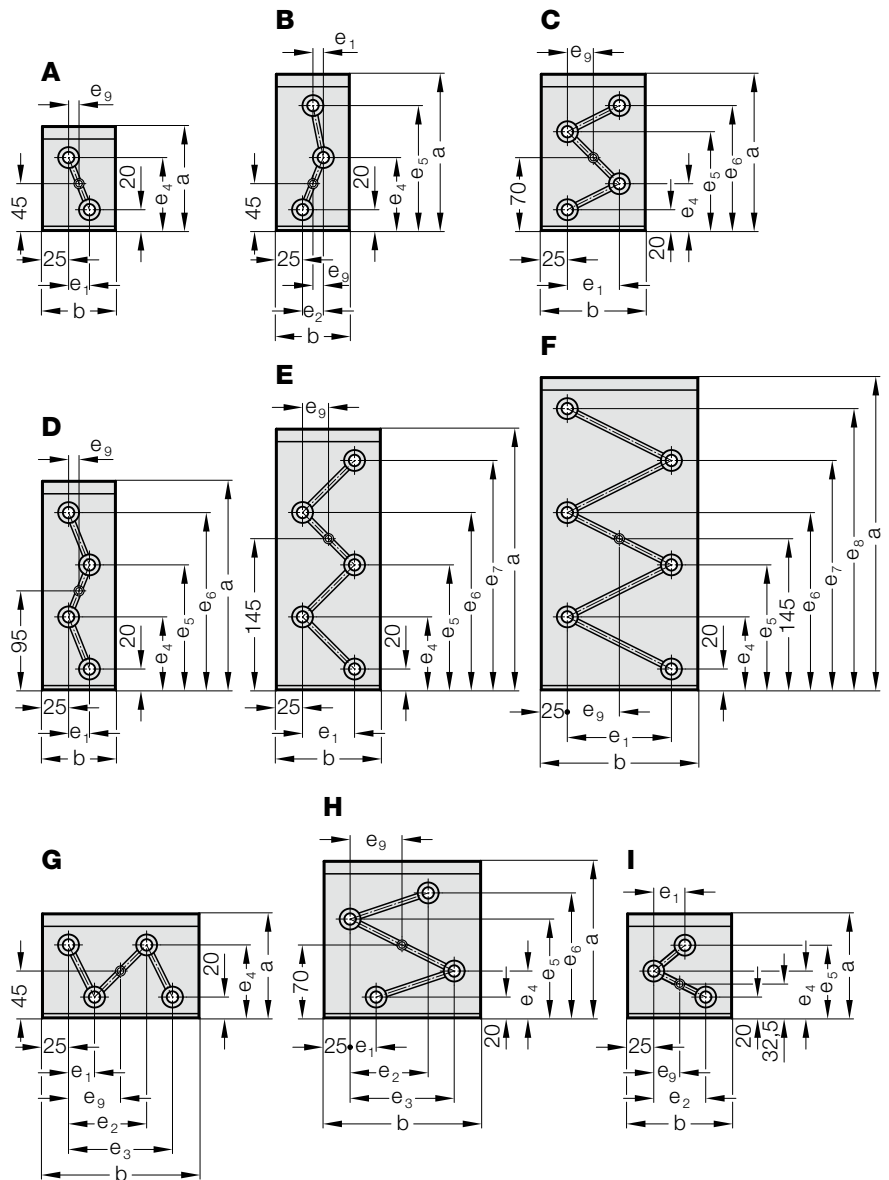

**Material:**

Steel, surface hardened


**Note:**

Screws are not included.

**Fixing:**

Use socket cap screws DIN EN ISO 4762 M10.

2960.44.45.

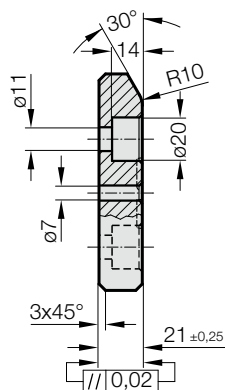

## SLIDING PAD, STEEL WITH OIL GROOVE, CNOMO

### 2960.44.45. Sliding pad, Steel with oil groove, CNOMO

Order No	Shape	b	a	e	e <sub>1</sub>	e <sub>2</sub>	e <sub>3</sub>	e <sub>4</sub>	e <sub>5</sub>	e <sub>6</sub>	e <sub>7</sub>	e <sub>8</sub>	e <sub>9</sub>	Number of screw holes
2960.44.45.070.100	A	70	100		20	-	-	70	-	-	-	-	10	2
2960.44.45.070.150	B	70	150		10	20	-	70	120	-	-	-	10	3
2960.44.45.070.200	D	70	200		20	-	-	70	120	170	-	-	10	4
2960.44.45.100.100	I	100	100		30	50	-	45	70	-	-	-	25	3
2960.44.45.100.150	C	100	150		50	-	-	45	95	120	-	-	25	4
2960.44.45.100.200	D	100	200		50	-	-	70	120	170	-	-	25	4
2960.44.45.100.250	E	100	250		50	-	-	70	120	170	220	-	25	5
2960.44.45.100.300	F	100	300		50	-	-	70	120	170	220	270	25	6
2960.44.45.150.100	G	150	100		25	75	100	70	-	-	-	-	50	4
2960.44.45.150.150	H	150	150		25	75	100	45	95	120	-	-	50	4
2960.44.45.150.200	D	150	200		100	-	-	70	120	170	-	-	50	4
2960.44.45.150.250	E	150	250		100	-	-	70	120	170	220	-	50	5
2960.44.45.150.300	F	150	300		100	-	-	70	120	170	220	270	50	6
2960.44.45.200.100	G	200	100		50	100	150	70	-	-	-	-	75	4