



PLAQUE DE FROTTEMENT, BRONZE AVEC LUBRIFIANT SOLIDE, NAAMS

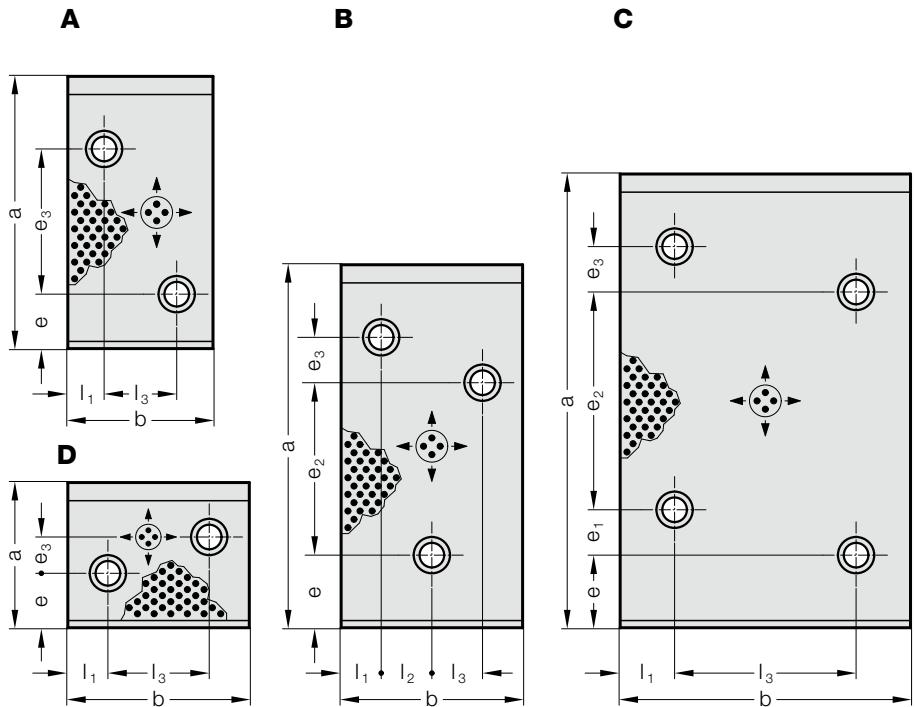

2960.79.



2960.79.

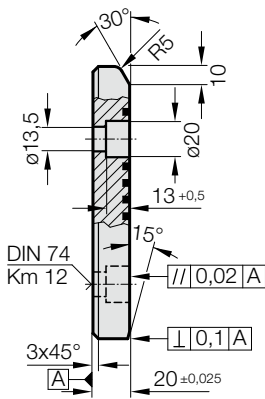

Matière :

Bronze avec lubrifiant solide

Remarque :

Livraison sans les vis.

Fixation :

Utiliser des vis à tête cylindrique
DIN EN ISO 4762 M12.

2960.79. Plaque de frottement, Bronze avec lubrifiant solide, NAAMS

| N° de commande | Forme | b | a | l ₁ | l ₂ | l ₃ | e | e ₁ | e ₂ | e ₃ | Nombre de perçages |
|-----------------|-------|-----|-----|----------------|----------------|----------------|----|----------------|----------------|----------------|--------------------|
| 2960.79.050.100 | A | 50 | 100 | 25 | - | - | 30 | - | - | 30 | 2 |
| 2960.79.050.150 | A | 50 | 150 | 25 | - | - | 30 | - | - | 80 | 2 |
| 2960.79.050.200 | A | 50 | 200 | 25 | - | - | 40 | - | - | 120 | 2 |
| 2960.79.080.100 | A | 80 | 100 | 20 | - | 40 | 30 | - | - | 30 | 2 |
| 2960.79.080.150 | A | 80 | 150 | 20 | - | 40 | 30 | - | - | 80 | 2 |
| 2960.79.080.200 | A | 80 | 200 | 20 | - | 40 | 40 | - | - | 120 | 2 |
| 2960.79.080.250 | A | 80 | 250 | 20 | - | 40 | 40 | - | - | 170 | 2 |
| 2960.79.080.315 | B | 80 | 315 | 20 | 20 | 20 | 40 | - | 210 | 25 | 3 |
| 2960.79.100.050 | D | 100 | 50 | 22 | - | 56 | 14 | - | - | 13 | 2 |
| 2960.79.100.080 | D | 100 | 80 | 22 | - | 56 | 30 | - | - | 20 | 2 |
| 2960.79.100.100 | A | 100 | 100 | 22 | - | 56 | 30 | - | - | 30 | 2 |
| 2960.79.100.150 | A | 100 | 150 | 22 | - | 56 | 30 | - | - | 80 | 2 |
| 2960.79.100.200 | B | 100 | 200 | 22 | 28 | 28 | 40 | - | 95 | 25 | 3 |
| 2960.79.100.250 | B | 100 | 250 | 22 | 28 | 28 | 40 | - | 145 | 25 | 3 |
| 2960.79.100.315 | B | 100 | 315 | 22 | 28 | 28 | 40 | - | 210 | 25 | 3 |
| 2960.79.125.080 | D | 125 | 80 | 25 | - | 75 | 30 | - | - | 20 | 2 |
| 2960.79.125.100 | A | 125 | 100 | 25 | - | 75 | 30 | - | - | 30 | 2 |
| 2960.79.125.150 | A | 125 | 150 | 25 | - | 75 | 30 | - | - | 80 | 2 |
| 2960.79.125.200 | B | 125 | 200 | 25 | 37 | 38 | 40 | - | 95 | 25 | 3 |
| 2960.79.125.250 | B | 125 | 250 | 25 | 37 | 38 | 40 | - | 145 | 25 | 3 |
| 2960.79.125.315 | C | 125 | 315 | 25 | - | 75 | 40 | 25 | 185 | 25 | 4 |
| 2960.79.160.100 | A | 160 | 100 | 30 | - | 100 | 30 | - | - | 30 | 2 |
| 2960.79.160.150 | A | 160 | 150 | 30 | - | 100 | 30 | - | - | 80 | 2 |
| 2960.79.160.200 | B | 160 | 200 | 30 | 50 | 50 | 40 | - | 95 | 25 | 3 |
| 2960.79.160.250 | C | 160 | 250 | 30 | - | 100 | 40 | 25 | 120 | 25 | 4 |
| 2960.79.160.315 | C | 160 | 315 | 30 | - | 100 | 40 | 25 | 185 | 25 | 4 |