




# Structural Blind Rivet FER<sup>®</sup>-BULB

## Series 10.791

**Stainless Steel / Stainless Steel**



- > Dome Head
- > open

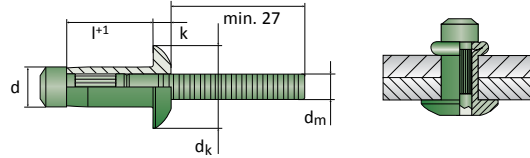

d	l +1		No.	
<b>4,0</b>	7,5	1,0 - 3,0	10.791.040.075	500
	10,0	3,0 - 5,0	10.791.040.100	500
	12,5	5,0 - 7,0	10.791.040.125	500
<b>d<sub>k</sub> 8,0</b>	<b>d<sub>m</sub> 2,6</b>	<b>k 1,5</b>	4,1 - 4,3 mm	5200 N  4000 N

d	l +1		No.	
<b>4,8</b>	10,0	1,5 - 3,5	10.791.048.100	500
	12,5	3,5 - 6,0	10.791.048.125	500
	15,5	6,0 - 8,5	10.791.048.155	250
<b>d<sub>k</sub> 9,6</b>	<b>d<sub>m</sub> 3,2</b>	<b>k 1,5</b>	4,9 - 5,1 mm	5500 N  5000 N

d	l +1		No.	
<b>6,4</b>	9,0	1,5 - 3,5	10.791.064.090	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	11000 N  8800 N

<b>6,4</b>	10,5	2,8 - 4,8	10.791.064.105	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	11500 N  8800 N

<b>6,4</b>	12,5	4,8 - 6,8	10.791.064.125	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	12500 N  8800 N

<b>6,4</b>	14,5	6,8 - 8,8	10.791.064.145	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	13000 N  8800 N

<b>6,4</b>	16,5	8,8 - 10,8	10.791.064.165	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	14000 N  8800 N

<b>6,4</b>	18,5	10,8 - 12,8	10.791.064.185	250
<b>d<sub>k</sub> 13,4</b>	<b>d<sub>m</sub> 3,9</b>	<b>k 2,7</b>	6,7 - 6,9 mm	15000 N  8800 N