 




Langschaftbruch-Blindniet FERO®-BULB

Serie 10.792



Stahl verzinkt / Stahl verzinkt

 Senkkopf <
offen <

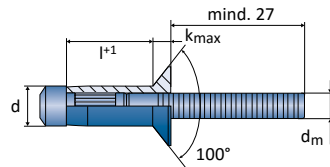

d	l +1		Nr.	
6,4	11,5	3,8 - 5,8	10.792.640.115	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	5300 N	5400 N
6,4	13,5	5,8 - 7,8	10.792.640.135	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	7300 N	5400 N
6,4	15,5	7,8 - 9,8	10.792.640.155	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	9300 N	5400 N

d	l +1		Nr.	
6,4	17,5	9,8 - 11,8	10.792.640.175	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	10300 N	5400 N
6,4	19,5	11,8 - 13,8	10.792.640.195	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	10300N	5400 N
6,4	21,5	13,8 - 15,8	10.792.640.215	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	10300N	5400 N
6,4	23,5	15,8 - 17,8	10.792.640.235	250
d _k 10,0	d _m 4,2	6,7 - 6,9 mm	10300N	5400 N