



Blind Rivet Nut HEXAFORM® FK




Series 10.868



C4C [1.0303]

Steel

  - > Flat Head
- > Hexagonal Shank
- > Open

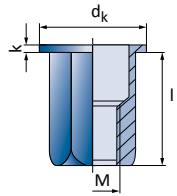

M		l	No.		
M4	0,5 - 2,0	10,0	10.868.040.200	500	
SW 6,0	k 1,0	d _k 9,0	l ₁ max. 7,5	↻ 5 Nm	↑ 5200 N
M5	0,5 - 3,0	12,5	10.868.500.000	500	
SW 7,0	k 1,0	d _k 10,0	l ₁ max. 8,5	↻ 7 Nm	↑ 9500 N
M6	0,5 - 3,0	14,5	10.868.600.000	500	
	3,0 - 5,5	17,0	10.868.060.550	500	
SW 9,0	k 1,5	d _k 13,0	l ₁ max. 10,5	↻ 13 Nm	↑ 16500 N

M		l	No.		
M8	0,5 - 3,0	17,5	10.868.800.000	250	
	3,0 - 6,0	20,5	10.868.080.600	250	
SW 11,0	k 1,5	d _k 15,0 16,0	l ₁ max. 13,0	↻ 25 Nm	↑ 23500 N
M10	1,0 - 4,5	22,0	10.868.100.450	250	
SW 13,0	k 2,0	d _k 19,0	l ₁ max. 16,5	↻ 55 Nm	↑ 37000 N
M12	1,5 - 5,0	25,0	10.868.120.500	100	
SW 16,0	k 2,0	d _k 23,0	l ₁ max. 19,0	↻ 85 Nm	↑ 56000 N

NEW

NEW

NEW