



Blind Rivet Nut HEXAFORM® KLSK-G





Series 10.887



C4C [1.0303]

Steel

   - > Small Countersunk Head
- > Hexagonal Shank
- > Closed

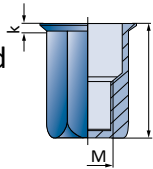

M		I	No.		
M4	0,5 - 2,5	16,0	10.887.040.250	500	
SW 6,0	SW ² 6,6	k 0,5	I ₁ max. 10,0	⌀ 5 Nm	↑ 5200 N
M5	0,5 - 3,0	20,0	10.887.050.300	500	
SW 7,0	SW ² 7,7	k 0,6	I ₁ max. 12,5	⌀ 7 Nm	↑ 9500 N
M6	0,5 - 3,0	22,0	10.887.060.300	500	
SW 9,0	SW ² 9,8	k 0,7	I ₁ max. 16,0	⌀ 13 Nm	↑ 16500 N

NEW

M		I	No.		
M8	0,5 - 3,5	25,5	10.887.080.350	250	
	3,0 - 6,0	28,0	10.887.080.600	250	
SW 11,0	SW ² 11,8	k 0,7	I ₁ max. 17,5	⌀ 25 Nm	↑ 23500 N
M10	1,0 - 3,5	28,0	10.887.100.350	250	
SW 13,0	SW ² 14,3	k 0,9	I ₁ max. 20,0	⌀ 55 Nm	↑ 37000 N

NEW

NEW