



 


# Blind Rivet Nut ASM-KLSK

## Series 10.851/10



**Aluminium**

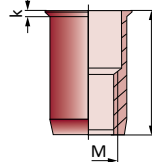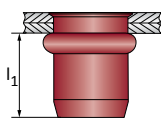

Small Countersunk Head <  
Round Shank <  
Open <

EN AW - 5754 [AlMg3]

M		I	No.			
<b>M4</b>	0,3 - 2,0	10,5	10.851.040.200/10			500
<b>D</b> 6,0	<b>k</b> 0,5	<b>d<sub>k</sub></b> 6,8	<b>l<sub>1</sub> max.</b> 6,5	2 Nm	2400 N	
<b>M5</b>	0,5 - 3,0	11,5	10.821.050.300/10			500
<b>D</b> 7,0	<b>k</b> 0,5	<b>d<sub>k</sub></b> 8,0	<b>l<sub>1</sub> max.</b> 7,5	4 Nm	4000 N	

M		I	No.			
<b>M6</b>	0,5 - 3,0	15,0	10.851.060.300/10			500
<b>D</b> 9,0	<b>k</b> 0,6	<b>d<sub>k</sub></b> 10,0	<b>l<sub>1</sub> max.</b> 9,0	6 Nm	6000 N	
<b>M8</b>	0,5 - 3,0	15,5	10.851.080.300/10			500
<b>D</b> 10,0	<b>k</b> 0,6	<b>d<sub>k</sub></b> 12,0	<b>l<sub>1</sub> max.</b> 11,5	18 Nm	10500 N	