

Blind Rivet Nut FLATSERT



Series 10.874



Steel

Small Countersunk Head <
Round Shank <
Open <

 For components with
INCH-product
imperial holes

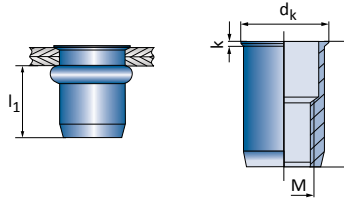

C4C [1.0303]

M		l	No.		
M3	0,5 - 2,0	8,7	10.874.300.000	500	
D 4,9	k 0,3	dk 5,3	l₁ max. 6,0	2 Nm	3000 N
M4	0,5 - 2,0	10,4	10.874.400.000	500	
D 6,4	k 0,4	dk 7,2	l₁ max. 8,0	3 Nm	6000 N
M5	0,5 - 3,2	12,0	10.874.500.000	500	
D 7,2	k 0,5	dk 8,1	l₁ max. 9,0	5 Nm	9500 N

M		l	No.		
M6	0,8 - 4,0	15,0	10.874.600.000	500	
D 9,6	k 0,5	dk 10,5	l₁ max. 11,0	10 Nm	13000 N
M8	1,0 - 4,0	16,0	10.874.800.000	500	
D 10,6	k 0,6	dk 11,5	l₁ max. 13,5	20 Nm	16000 N
M10	1,0 - 5,0	22,5	10.874.100.000	250	
D 12,7	k 0,6	dk 13,9	l₁ max. 16,5	40 Nm	19500 N