

 



Blind Rivet Nut SSM-G

Series 10.857

Steel

- > Countersunk Head
- > Round Shank
- > Closed

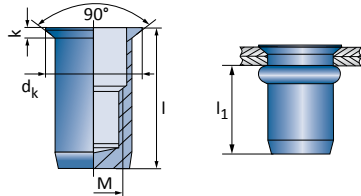

C4C [1.0303]

M		l	No.	
M5	1,5 - 4,0	19,5	10.857.050.400	500
D 7,0	k 1,5	dk 9,3	l₁ max. 15,5	6 Nm 9500 N
M6	1,5 - 4,5	23,5	10.857.060.450	500
	4,5 - 6,0	25,0	10.857.060.600	500
D 9,0	k 1,5	dk 11,3	l₁ max. 18,5	11 Nm 16500 N

M		l	No.	
M8	1,5 - 4,5	28,0	10.857.080.450	250
	4,5 - 6,0	29,5	10.857.080.600	250
D 11,0	k 1,5	dk 13,3	l₁ max. 23,0	24 Nm 23500 N
M10	1,5 - 3,0	30,5	10.857.100.300	250
	3,0 - 4,5	32,0	10.857.100.450	250
D 13,0	k 1,5	dk 14,9	l₁ max. 28,5	50 Nm 37000 N