



Blind Rivet Nut SSM-KLSK

Series 10.841



Steel

 Small Countersunk Head <
Round Shank <
Open <

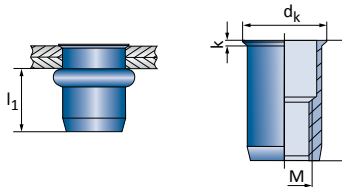

C4C [1.0303]

M		I	No.		
M4	0,5 - 2,0	10,0	10.841.040.200	500	
D 6,0	k 0,5	dk 7,0	l₁ max. 8,0	3 Nm	5000 N
M5	0,5 - 3,0	12,0	10.841.050.300	500	
D 7,0	k 0,5	dk 8,0	l₁ max. 9,0	5 Nm	9000 N

M		I	No.		
M6	0,5 - 3,0	15,0	10.841.060.300	500	
D 9,0	k 0,5	dk 10,0	l₁ max. 14,5	10 Nm	15000 N
M8	0,5 - 3,0	16,0	10.841.080.300	500	
D 11,0	k 0,5	dk 12,0	l₁ max. 16,0	20 Nm	20000 N