




Blind Rivet Nut SSM

Series 10.853

Steel

- > Countersunk Head
- > Round Shank
- > Open

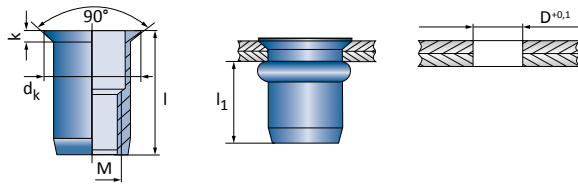

C4C [1.0303]

M		I	No.		
M4	1,5 - 3,5	11,5	10.853.040.350	500	
	3,0 - 5,0	13,0	10.853.040.500	500	
D 6,0	k 1,5	d_k 8,3	l₁ max. 8,0	4 Nm	5200 N
M5	1,5 - 4,0	13,0	10.853.050.400	500	
	4,0 - 5,5	14,5	10.853.050.550	500	
D 7,0	k 1,5	d_k 9,3	l₁ max. 9,0	6 Nm	9500 N
M6	1,5 - 4,5	16,0	10.853.060.450	500	
	4,5 - 6,0	17,5	10.853.060.600	500	
D 9,0	k 1,5	d_k 11,3	l₁ max. 11,0	11 Nm	16500 N

NEW

M		I	No.		
M8	1,5 - 4,5	18,5	10.853.080.450	250	
	4,5 - 6,0	20,0	10.853.080.600	250	
D 11,0	k 1,5	d_k 13,3	l₁ max. 13,5	24 Nm	23500 N
M10	1,5 - 4,5	22,0	10.853.100.450 ¹	250	
	4,0 - 6,0	25,0	10.853.100.600 ¹	250	
	6,0 - 9,0	28,0	10.853.100.900 ²	250	
D 13,0	k 1,5	d_k¹14,9/²15,7	l₁ max. 16,5	50 Nm	37000 N