

 
 
 



# Blind Rivet Nut HEXATOP®-E-KLSK A4

Series 10.879/79 **NEW**

## Stainless Steel A4

- > Small Countersunk Head
- > Partial Hexagonal Shank
- > Open

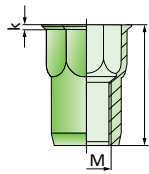

M		I	No.		
<b>M4</b>	0,5 - 2,0	10,0	10.879.040.200/79	500	
SW 6,0	SW <sup>2</sup> 6,8	k 0,5	l <sub>1</sub> max. 8,5	5 Nm	↑ 6500 N
<b>M5</b>	0,5 - 2,0	12,0	10.879.050.200/79	500	
SW 7,0	SW <sup>2</sup> 8,0	k 0,6	l <sub>1</sub> max. 9,0	8 Nm	↑ 10000 N

**NEW**

**NEW**

M		I	No.		
<b>M6</b>	0,5 - 2,5	14,0	10.879.060.250/79	500	
SW 9,0	SW <sup>2</sup> 10,0	k 0,6	l <sub>1</sub> max. 10,0	15 Nm	↑ 15000 N
<b>M8</b>	0,5 - 3,5	16,5	10.879.080.350/79	500	
SW 11,0	SW <sup>2</sup> 12,0	k 0,6	l <sub>1</sub> max. 11,5	26 Nm	↑ 25000 N

**NEW**

**NEW**