





Polymer, one-piece

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible

Moving end with bore
(outer link) 040...1(PZ)

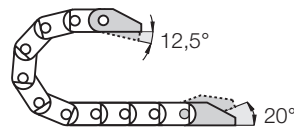


 040...2(PZ) Fixed end
with pin (inner link)




Possible installation conditions for assembled mounting brackets ▶ Order example "preassembled" below

040...1(PZ)
Moving end

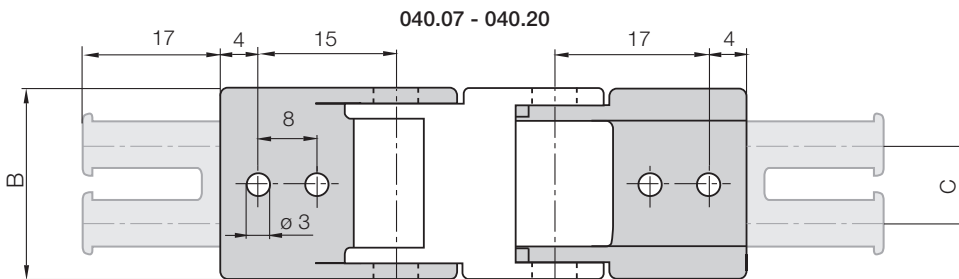

040...2(PZ)
Fixed end

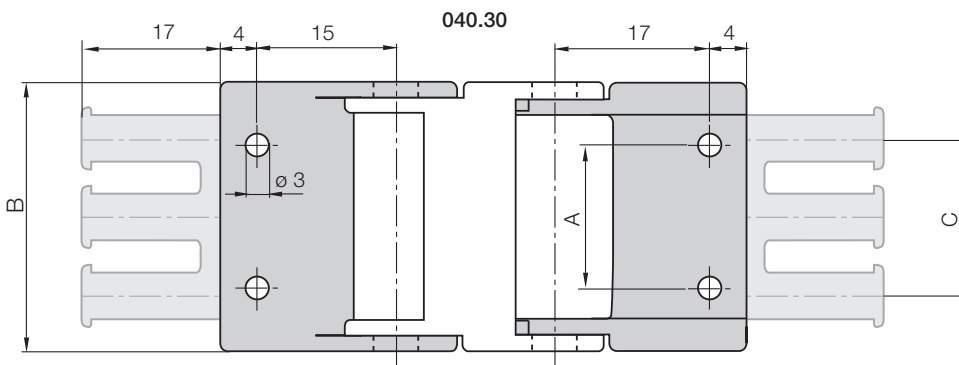


Dimensions and order configurations

For E-Chain®	Part No. full set	Part No. full set zahl	Number of teeth	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
04.07. ▶	040.07. 12 PZ	040.07. 12	1	-	13	-
04.10. ▶	040.10. 12 PZ	040.10. 12	1	-	15	-
04.16. ▶	040.16. 12 PZ	040.16. 12	2	-	21	10
04.20. ▶	040.20. 12 PZ	040.20. 12	2	-	25	10
04.30. ▶	040.30. 12 PZ	040.30. 12	3	22	35	20

For the **preassembled** mode please add the index **A1...A4** e.g. 040.10. 12 PZ **A1**

Part No. structure

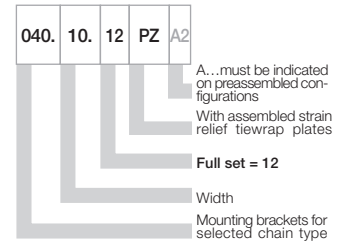

Full set, for both ends:

040. 10. 12 PZ +tie-wrap plate

Single-part order:

040. 10. 1 PZ +tie-wrap plate

Mounting bracket **with bore**

040. 10. 2 PZ +tie-wrap plate

Mounting bracket **with pin**



Quicksnap - the complete, detachable mounting unit, upon request **Part No. 040.07.QS**



Quickfix - mounting bracket with dowel, upon request

Additional Features

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

