
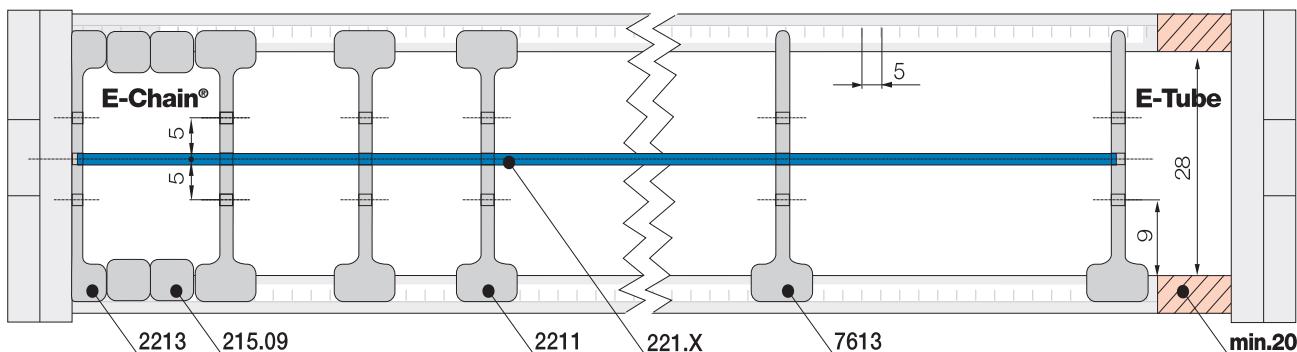
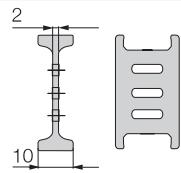


Option 1 | Separators and spacers* (*side-mounted applications)


Note E-Tube: Please observe a lateral spacing of **20 mm** to the seidelinks!
In the standard configuration separators are assembled every 2nd E-Chain® link!

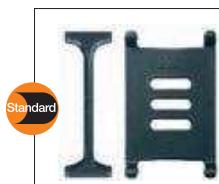

Separator for E-Chains®
unassembled **2201**
assembled **2211**

Separator 2201 (E-Chains® only)


is used when vertical and horizontal separation is required. Due to its slot, it allows basic vertical/horizontal shelving arrangements.

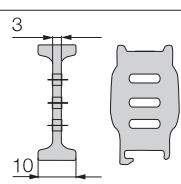

Separator for E-Tubes
unassembled **7603**
assembled **7613**

Separator 7603 (E-Tubes only)


For E-Tubes R4.28.

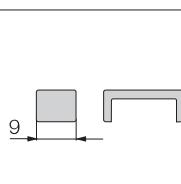

Spacer for E-Chains®
unassembled **205.09**
assembled **215.09**

Spacer* 205.09 (E-Chains® only)

Separators can be fixed in position by spacers. The available interior height is reduced by 2 mm per spacer (4 mm when spacers are fitted on both sides). To avoid this, the parts can also be installed from the outside on the opening crossbar. (not for long travel applications).

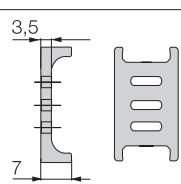


Side plate for E-Chains®
unassembled **2203**
assembled **2213**

Side plate 2203 (E-Chains® only)

Works like separator.

Allows modular shelving close to the side links.

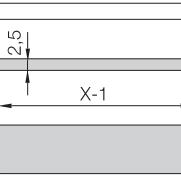

Full-width shelf (40-200 mm)
unassembled **220.X**
assembled **221.X**


Full-width shelf 220.X

This option makes sense in applications with many thin cables with similar diameters. Full-width shelves can be arranged at 3 different heights (in 5 mm increments).





Full-width shelf

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
040	220.40	221.40	075	220.75	221.75	150	220.150	221.150
050	220.50	221.50	087	220.87	221.87	175	220.175	221.175
062	220.62	221.62	100	220.100	221.100	200	220.200	221.200
070	220.70	221.70	125	220.125	221.125			

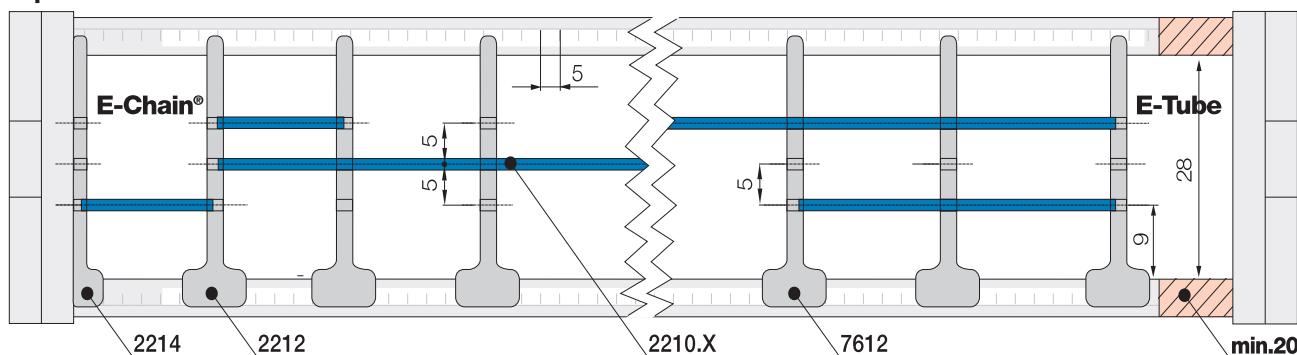

Option 2 | Shelves

In the standard configuration separators are assembled every 2nd E-Chain® link !

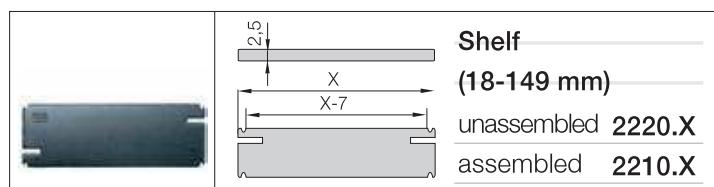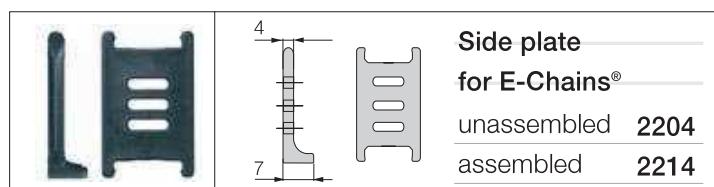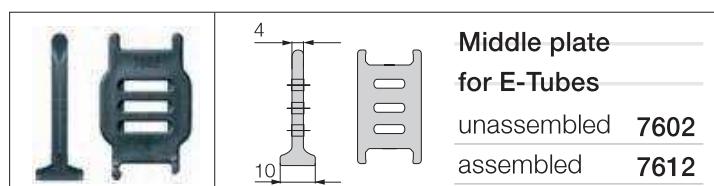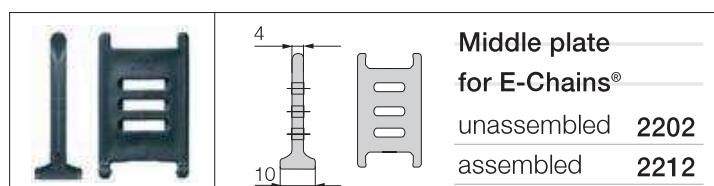**Middle plate 2202 (E-Chains® only)**

To achieve a modular shelving by shelf 2220.X arranged at 3 different heights (in 5 mm increments).

Middle plate 7602 (E-Tubes only)

For E-Tubes R4.28.
A side plate is not available for the E-Tube.

Side plate 2204 (E-Chains® only)

Works like middle plate.
Allows modular shelving close to the side links.

Shelf 2220.X

For horizontal separation. Shelves of various widths can be arranged at 3 different heights (in 5 mm increments).

Shelves

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
018	2200.18	2210.18	043	2200.43	2210.43	088	2200.88	2210.088
023	2200.23	2210.23	048	2200.48	2210.48	099	2200.99	2210.099
028	2200.28	2210.28	058	2200.58	2210.58	124	2200.124	2210.124
033	2200.33	2210.33	068	2200.68	2210.68	149	2200.149	2210.149
038	2200.38	2210.38	073	2200.73	2210.73			



For your online order, more products variety and configuration also use
 ► www.igus.de/en/E4.28 ► www.igus.de/en/R4.28