


### Standard - for any application


Separator with a wide base for maximum holding strength in the e-chain®.

\*Available upon request. Please consult igus® for delivery time.

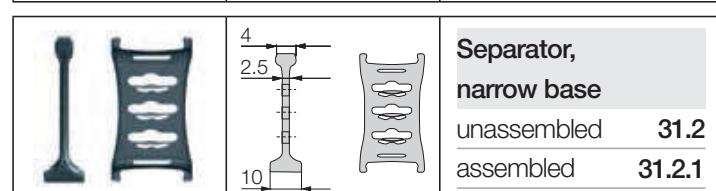

### For even faster installation


Wide on one side for high holding strength, narrow on opposite side for easy cable fitting.

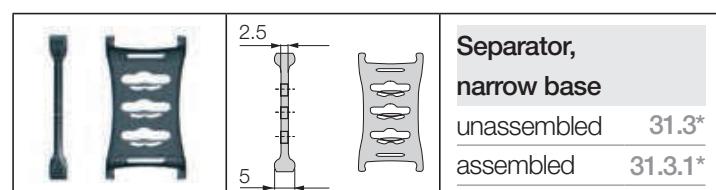

### For small cables


Separator with a narrow base for a large number of small cables side by side. Saves space in the e-chain®.

\*Available upon request. Please consult igus® for delivery time.

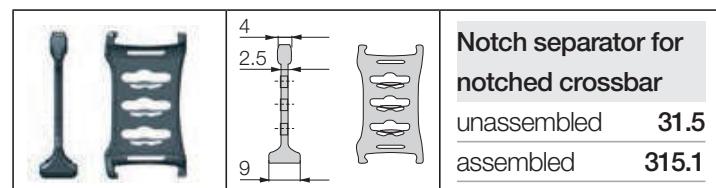

### Locks securely in preset increments

Notch separator for exact positioning in e-chains®. Recommended for side-mounted applications.

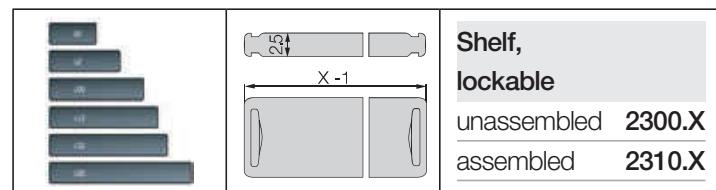

### Horizontal separation

Full-width shelf locks securely into separators at both ends, giving a fixed width. Can be used as full-width or partial shelf.

### Shelves

Width = X [mm]



| X [mm] | unassembled | assembled | X [mm] | unassembled | assembled | X [mm] | unassembled | assembled |
|--------|-------------|-----------|--------|-------------|-----------|--------|-------------|-----------|
| 015    | 2300.015    | 2310.015  | 060    | 2300.060    | 2310.060  | 087    | 2300.087    | 2310.087  |
| 025    | 2300.025    | 2310.025  | 062    | 2300.062    | 2310.062  | 090    | 2300.090    | 2310.090  |
| 030    | 2300.030    | 2310.030  | 065    | 2300.065    | 2310.065  | 100    | 2300.100    | 2310.100  |
| 038    | 2300.038    | 2310.038  | 070    | 2300.070    | 2310.070  | 103    | 2300.103    | 2310.103  |
| 040    | 2300.040    | 2310.040  | 075    | 2300.075    | 2310.075  | 110    | 2300.110    | 2310.110  |
| 050    | 2300.050    | 2310.050  | 077    | 2300.077    | 2310.077  | 120    | 2300.120    | 2310.120  |
| 057    | 2300.057    | 2310.057  | 080    | 2300.080    | 2310.080  | 125    | 2300.125    | 2310.125  |