


Interior separation | Increase cable service life

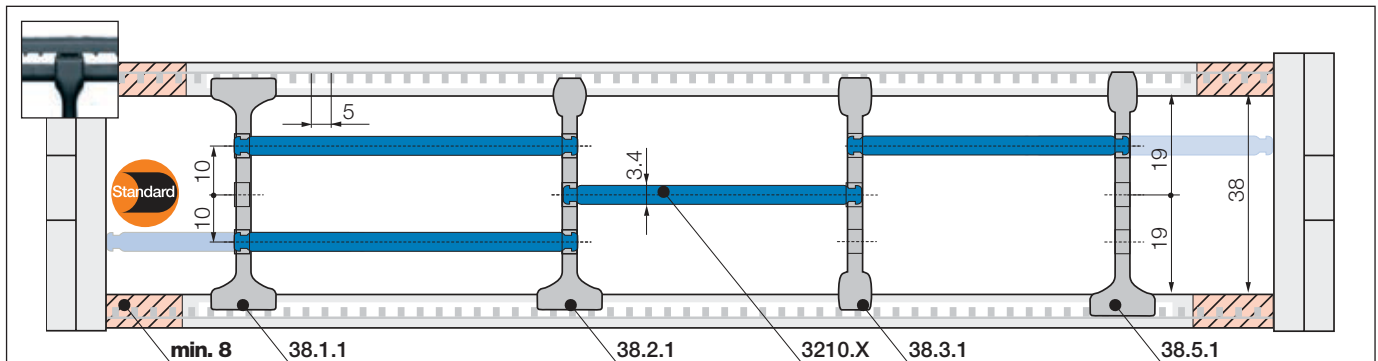

Note: please be aware of the minimum lateral gap to the side links! e-tube: 8 mm | e-chain®: 8 mm
As standard igus® separators should be fitted every 2nd e-chain® link!

| | | | | | |
|----------|--|--|---|---------------------------|-------------------------|
| Standard | | | Standard separator, wide base | unassembled 38.1 | assembled 38.1.1 |
| | | | Separator, narrow base | unassembled 38.2 | assembled 38.2.1 |
| | | | Separator, narrow base | unassembled 38.3 | assembled 38.3.1 |
| | | | Notch separator for notched crossbar | unassembled 38.5 | assembled 38.5.1 |
| | | | Shelf, lockable | unassembled 3200.X | assembled 3210.X |

Standard - for any application

Separator with a wide base for maximum holding strength in the e-chain®.

For even faster installation

Wide on one side for high holding strength, narrow on opposite side for easy cable fitting.

For small cables

Separator with a narrow base for a large number of small cables side by side. Saves space in the e-chain®.

Locks securely in preset increments

Notch separator for exact positioning in e-chains®. Recommended for side-mounted applications.

Horizontal separation

Full-width shelf locks securely into separators at both ends, giving a fixed width. Can be used as full-width or partial shelf.

Shelves

Width = X [mm]



| X [mm] | unassembled | assembled | X [mm] | unassembled | assembled | X [mm] | unassembled | assembled |
|--------|-------------|-----------|--------|-------------|-----------|--------|-------------|-----------|
| 050 | 3200.050 | 3210.050 | 125 | 3200.125 | 3210.125 | 225 | 3200.225 | 3210.225 |
| 075 | 3200.075 | 3210.075 | 150 | 3200.150 | 3210.150 | 250 | 3200.250 | 3210.250 |
| 100 | 3200.100 | 3210.100 | 175 | 3200.175 | 3210.175 | | | |
| 115 | 3200.115 | 3210.115 | 200 | 3200.200 | 3210.200 | | | |

Split separators - universal retrofit - New

- Separators can be divided in the middle for speedy assembly
- Allows fast filling anywhere in the e-chain® from above or below.
- 2 types available: with wide or narrow base

More information ► upon request

