


KMA mounting brackets | Attachment from any side | Pivoting | Locking


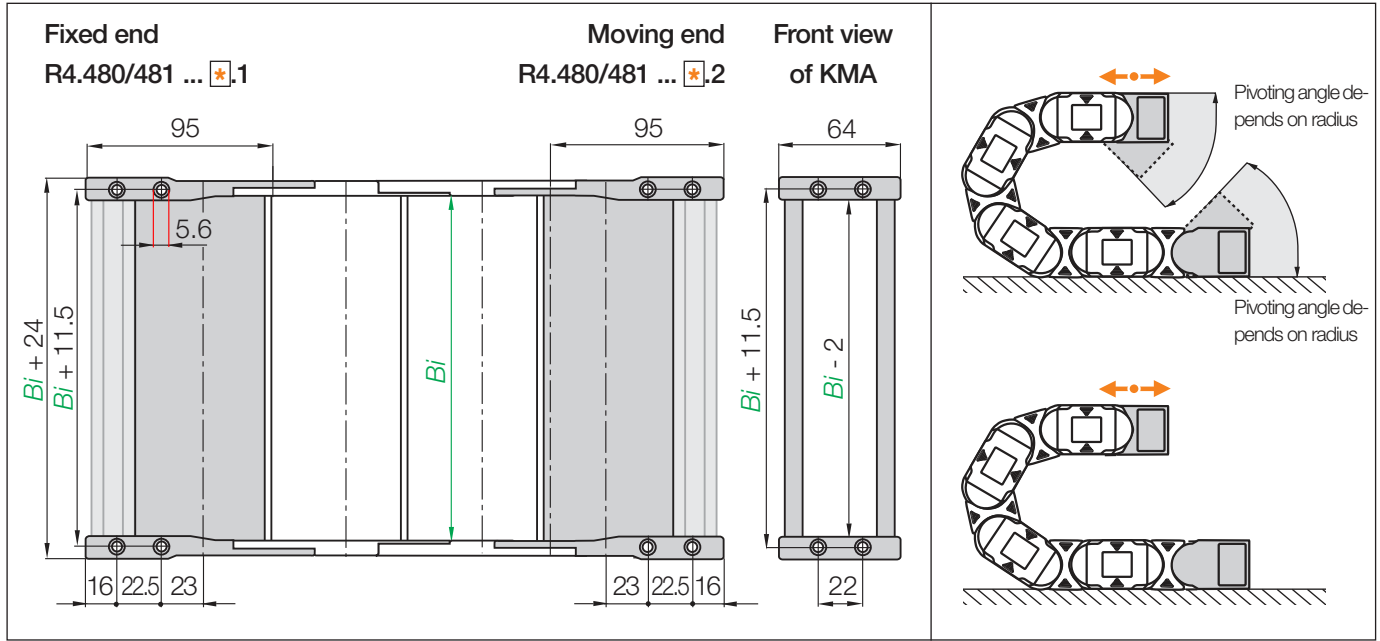


KMA pivoting | Recommended for unsupported and gliding applications
KMA locking | Recommended for vertical hanging and standing applications

Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]	Width index	Part No. full set KMA pivoting	Part No. full set KMA locking	Bi [mm]
050.	R4.480.050.*.12.C	R4.481.050.*.12.C	050	150.	R4.480.150.*.12.C	R4.481.150.*.12.C	150
062.	R4.480.062.*.12.C	R4.481.062.*.12.C	062	175.	R4.480.175.*.12.C	R4.481.175.*.12.C	175
075.	R4.480.075.*.12.C	R4.481.075.*.12.C	075	200.	R4.480.200.*.12.C	R4.481.200.*.12.C	200
087.	R4.480.087.*.12.C*	R4.481.087.*.12.C*	087	250.	R4.480.250.*.12.C*	R4.481.250.*.12.C*	250
100.	R4.480.100.*.12.C	R4.481.100.*.12.C	100	300.	R4.480.300.*.12.C*	R4.481.300.*.12.C*	300
125.	R4.480.125.*.12.C	R4.481.125.*.12.C	125				

(KMA = polymer metal mounting bracket) For the C-profile option please add index **C**

*Width available upon request. Please consult igus® for delivery time.

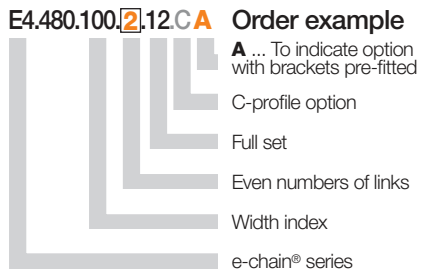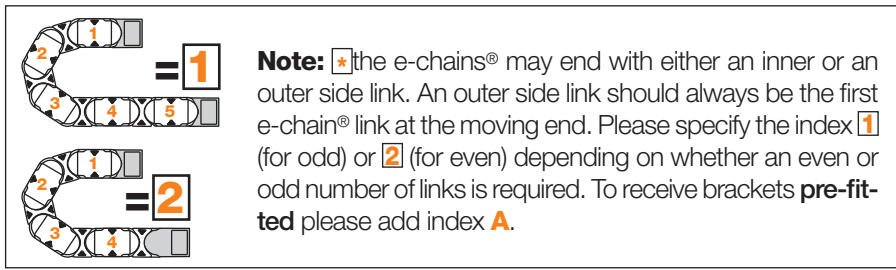

Strain relief e.g. clamps, tiwrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with ordering options ▶ From page 1098