

Typ Type **BB - 623 - B180 - 10 - ES**

xirodur® Material Käfig/Kugel cage/balls


Kugellager Ball Bearing

Baugröße Size

Ringmaterial Race material

Käfigmaterial Cage material

Kugelmaterail Ball material

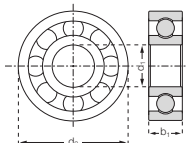

Abmessungen Dimensions [mm]

Bau- größe Size	InnenØ Inner Ø d1	AußenØ Outer Ø d2	Breite Width b1	Kugellager Ringmaterialien Ball bearing material of rings						Art. Nr. Part No.
				B180	S180	F180	D180	C160	A500	
623	3	10	4	●	●	●	●	●	●	BB-623-□-□-ES*
633	3	13	5	●	●					BB-633-□-□-ES*
684	4	9	4	●	●					BB-684-□-□-ES*
694	4	11	4	●	●					BB-694-□-□-ES*
604	4	12	4	●	●					BB-604-□-□-ES*
624	4	13	5	●	●	●	●	●	●	BB-624-□-□-ES*
634	4	16	5	●	●					BB-634-□-□-ES*
685	5	11	5	●	●					BB-685-□-□-ES*
695	5	13	5	●	●					BB-695-□-□-ES*
605	5	14	5	●	●					BB-605-□-□-ES*
625	5	16	5	●	●	●	●	●	●	BB-625-□-□-ES*
635	5	19	6	●	●			●	●	BB-635-□-□-ES*
686	6	13	5	●	●					BB-686-□-□-ES*
696	6	15	5	●	●					BB-696-□-□-ES*
606	6	17	6	●	●					BB-606-□-□-ES*
626	6	19	6	●	●	●	●	●	●	BB-626-□-□-ES*
636	6	22	7	●	●			●	●	BB-636-□-□-ES*
687	7	14	5	●	●					BB-687-□-□-ES*
697	7	17	5	●	●					BB-697-□-□-ES*
607	7	19	6	●	●					BB-607-□-□-ES*
627	7	22	7	●	●			●	●	BB-627-□-□-ES*
688	8	16	5	●	●			●	●	BB-688-□-□-ES*
698	8	19	6	●	●					BB-698-□-□-ES*
608	8	22	7	●	●	●	●	●	●	BB-608-□-□-ES*
628	8	24	8	●	●			●	●	BB-628-□-□-ES*
638	8	28	9	●	●			●	●	BB-638-□-□-ES*
689	9	17	5	●	●					BB-689-□-□-ES*
699	9	20	6	●	●					BB-699-□-□-ES*
609	9	24	7	●	●					BB-609-□-□-ES*

Ringmaterial Race material

- B180:** Kostengünstig Cost-effective
- S180:** Geringer Verschleiß Low wear
- F180:** ESD-Schutz ESD protection
- D180:** Hohe Geschwindigkeiten High speeds
- C160:** Chemikalienbeständig Chemical-resistant
- A500:** Chemie/Hohe Temperaturen Chemical/High temperatures

Käfigmaterial Cage material

- 10:** PA (für Ringmaterial for race material B180/S180/F180/D180/A500)
- 20:** PP (für Ringmaterial for race material C160)
- 30:** xirodur® B180 (für Ringmaterial for race material B180)
- 50:** PE (für Ringmaterial for race material B180/F180)
- 70:** PEEK (für Ringmaterial for race material A500)

Kugelmaterail Ball material

- ES:** Edelstahl stainless steel
- GL:** Glas glass

Bau- größe Size	InnenØ Inner Ø d1	AußenØ Outer Ø d2	Breite Width b1	Kugellager Ringmaterialien Ball bearing material of rings						Art. Nr. Part No.
				B180	S180	F180	D180	C160	A500	
629	9	26	8	●	●			●	●	BB-629-□-□-ES*
6800	10	19	5	●	●			●	●	BB-6800-□-□-ES*
6900	10	22	6	●	●					BB-6900-□-□-ES*
6000	10	26	8	●	●	●	●	●	●	BB-6000-□-□-ES*
6200	10	30	9	●	●			●	●	BB-6200-□-□-ES*
6300	10	35	11	●	●					BB-6300-□-□-ES*
6701	12	18	4	●	●					BB-6701-□-□-ES*
6801	12	21	5	●	●			●	●	BB-6801-□-□-ES*
6901	12	24	6	●	●					BB-6901-□-□-ES*
6001	12	28	8	●	●	●	●	●	●	BB-6001-□-□-ES*
6201	12	32	10	●	●			●	●	BB-6201-□-□-ES*
6301	12	37	12	●	●					BB-6301-□-□-ES*
6702	15	21	4	●	●					BB-6702-□-□-ES*
6802	15	24	5	●	●			●	●	BB-6802-□-□-ES*
6902	15	28	7	●	●					BB-6902-□-□-ES*
6002	15	32	9	●	●	●	●	●	●	BB-6002-□-□-ES*
6202	15	35	11	●	●			●	●	BB-6202-□-□-ES*
6302	15	42	13	●	●					BB-6302-□-□-ES*
6703	17	23	4	●	●					BB-6703-□-□-ES*
6803	17	26	5	●	●			●	●	BB-6803-□-□-ES*
6903	17	30	7	●	●					BB-6903-□-□-ES*
6003	17	35	10	●	●	●	●	●	●	BB-6003-□-□-ES*
6203	17	40	12	●	●			●	●	BB-6203-□-□-ES*
6303	17	47	14	●	●					BB-6303-□-□-ES*
6704	20	27	4	●	●					BB-6704-□-□-ES*
6804	20	32	7	●	●			●	●	BB-6804-□-□-ES*
6904	20	37	9	●	●					BB-6904-□-□-ES*
6004	20	42	12	●	●	●	●	●	●	BB-6004-□-□-ES*
6204	20	47	14	●	●			●	●	BB-6204-□-□-ES*
6304	20	52	15	●	●					BB-6304-□-□-ES*
6705	25	32	4	●	●					BB-6705-□-□-ES*
6805	25	37	7	●	●			●	●	BB-6805-□-□-ES*
6905	25	42	9	●	●					BB-6905-□-□-ES*
6005	25	47	12	●	●	●		●	●	BB-6005-□-□-ES*
6205	25	52	15	●	●			●	●	BB-6205-□-□-ES*
6305	25	62	17	●	●					BB-6305-□-□-ES*
6706	30	37	4	●	●					BB-6706-□-□-ES*
6806	30	42	7	●	●					BB-6806-□-□-ES*
6906	30	47	9	●	●					BB-6906-□-□-ES*
6006	30	55	13	●	●				●	BB-6006-□-□-ES*
6206	30	62	16	●	●					BB-6206-□-□-ES*
6306	30	72	19	●	●					BB-6306-□-□-ES*

* alternativ mit Glaskugeln, Suffix "-GL" also with glass balls, suffix "-GL"



Lieferbar Available

- ab Lager from stock
- Lieferzeit 3 Wochen nach Rücksprache delivery time 3 weeks after consultation



www.igus.de/xiros
www.igus.eu/xiros