


482.6 mm (19") installation system

482.6 mm (19") installation

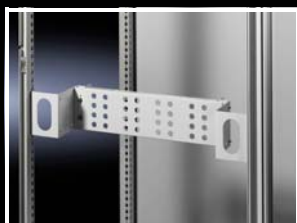

Adaptor kit, 3 U

for 800 mm wide TS enclosures

For fastening individual 482.6 mm (19") components, or as an additional mounting facility at the rear of the enclosure. The mounting level in the adaptor angle can be adjusted in 25 mm increments by up to 100 mm in the depth, leaving sufficient space for buying where patch panels or splicing boxes are used. Attachment is on the inner mounting level of the frame section or a suitable chassis in the enclosure depth.

Material:

– Sheet steel

Colour:

– RAL 7035

Height	Mounting position	Packs of	Model No.
3 U	Centre	2 pc(s).	7246.100



Adaptor, 3 U

Depth offset 100 mm

This adaptor is used to recess 482.6 mm (19") mounting of equipment inside enclosures with 482.6 mm (19") installation in the foremost position, such as server or electronic enclosures. In this way, sufficient space can be gained in front of the mounting equipment to integrate patch panels or switches, whilst at the same time exploiting the maximum enclosure depth.

Material:

– Sheet steel

Surface finish:

– Zinc-plated

Supply includes:

– Assembly parts

Packs of	Model No.
2 pc(s).	7246.400



Adaptor, metric to 21"/19"

With this adaptor, 482.6 mm (19") assemblies may be fastened to metric (535 mm) mounting angles, or combined systems may be configured.

Material:

– Extruded aluminium section

Supply includes:

– Assembly parts

SU	U	Packs of	Model No.
2	1	2 pc(s).	7246.010
6	3	2 pc(s).	7246.030
11	6	2 pc(s).	7246.060