


Network/server enclosures TS-IT

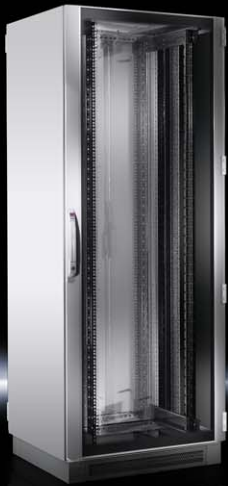

IT power Page 387 System accessories Page 507 Monitoring Page 445 Climate control Page 307

Material:

- Sheet steel
- Glazed door: Single-pane safety glass, 3 mm

Surface finish:

- Enclosure frame: Dipcoat-primed
- Interior installation: Primed
- Doors and roof: Dipcoat-primed, powder coated

Colour:

- Enclosure frame and panels: RAL 7035
- Interior installation: RAL 9005

Load capacity of the 482.6 mm (19") mounting angles:

- 15000 N

Supply includes:

- TS 8 enclosure frame with doors and roof plate
- Please note the product-specific scope of supply.

Note:

- Depending on the siting type and location, the door opening may vary for selected applications

Technical details:

Available on the Internet

with glazed door for rack climate control, pre-configured

Units U	Packs of		42	Page
Width mm			800	
Height mm			2100	
Depth mm			800	
Distance between levels, pre-configured mm			545	
Model No.	1 pc(s).		5507.150	
Product-specific scope of supply				
Glazed aluminium door at the front, 180° hinges	1 pc(s).		■	
Sheet steel door at the rear, vertically divided, 180° hinges	1 pc(s).		■	
Lock front and rear: Comfort handle for semi-cylinders and security lock 3524 E	1 pc(s).		■	
Two 482.6 mm (19") mounting sections front and rear, variably mounted on support strips with quick-release fasteners			■	
Roof plate, multi-piece, removable, with side cable entry in the depth and covered cut-out for fan mounting plate	1 pc(s).		■	
Spacers to raise the fan cover plate, for passive cooling (supplied loose)	4 pc(s).		■	
Potential equalisation incl. central earthing point, pre-configured	1 set(s)		■	
Multi-tooth screws M5, cage nuts M5, conductive (supplied loose)	50 pc(s).		■	
Base mount	1 pc(s).		■	
Base module mounted at front as infill panel	1 pc(s).		■	
Flex-Block base/plinth 100 mm, vented	1 set(s)		■	
Side panels, one-piece, lockable	2 pc(s).		■	
Levelling feet incl. base/plinth adaptor sleeve (supplied loose)	1 set(s)		■	
Accessories				
Gland plates	1 set(s)		5502.530	529
Fan mounting plates	1 pc(s).		5502.020	437
Air baffle plates	1 set(s)		5501.815	692
Cable route	1 pc(s).		5502.120	672
Cable duct	1 pc(s).		5502.105	673
Component shelves			from page	627
Slide rails			from page	687