

One-piece consoles TP



System accessories Page 507 Monitors, keyboards Page 706/707 Climate control Page 307 One-piece consoles, stainless steel Page 186

Material:

- Enclosure: Sheet steel 1.5 mm
- Door and console cover: Sheet steel, 2.0 mm, all-round foamed-in PU seal
- Mounting plate: Sheet steel 3.0 mm

Surface finish:

- Enclosure, cover and door: Dipcoat-primed, powder-coated on the outside, textured paint
- Mounting plate: Zinc-plated

Colour:

- RAL 7035

Protection category IP to IEC 60 529:

- IP 55 with selection of the appropriate gland plates

Protection category NEMA:

- NEMA 12 with selection of the appropriate gland plates

Supply includes:

- Enclosure, solid back and sides
- Door or double door at front, with locking rod
- Mounting plate
- Cover hinged at rear, 2 stays with automatic locking. Automatic unlocking on the left, manual unlocking on the right
- Open base for individual cable entry

Note:


- With the two-door variant, the base opening is divided in two, and two sets of gland plates are required.

Approvals:

- UL
- cUL

Technical details:

Available on the Internet

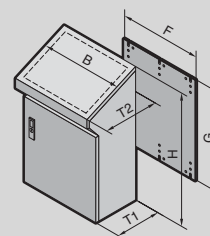

Width (B) mm	Packs of	600	800	1000	1200	Page
Height (H) mm		960	960	960	960	
Depth, bottom (T1) mm		400	400	400	400	
Depth, top (T2) mm		520	520	520	520	
Mounting plate width (F) mm		530	730	930	1130	
Mounting plate height (G) mm		900	900	900	900	
Model No.	1 pc(s).	6746.500	6748.500	6740.500	6742.500	
Door(s)		1	1	2	2	

Accessories

Base/plinth components, front and rear, 100 mm	1 set(s)	8601.600	8601.800	8601.000	8601.200	513
Base/plinth trim panels, side, 100 mm	1 set(s)	8601.040	8601.040	8601.040	8601.040	514
Base/plinth components, front and rear, 200 mm	1 set(s)	8602.600	8602.800	8602.000	8602.200	513
Base/plinth trim panels, side, 200 mm	1 set(s)	8602.040	8602.040	8602.040	8602.040	514
Cross member	2 pc(s).	8601.450	8601.450	8601.450	8601.450	520
Gland plates		see page	see page	see page	see page	525
Rails for interior installation	4 pc(s).	see page	5001.051	see page	see page	598
TS punched section with mounting flange, 17 x 73 mm		see page	see page	see page	see page	606
TS punched rail 18 x 38 mm	4 pc(s).	8612.240	8612.240	8612.240	8612.240	609
Cable clamp rails	1 pc(s).	5001.080	5001.081	5001.082	5001.083	665
Sheet steel wiring plan pockets	1 pc(s).	4116.500	4118.500	4115.500	4116.500	578
TP aluminium strip	1 pc(s).	6731.120	6731.120	6731.120	6731.120	117
Lock systems		from page	from page	from page	from page	562