



System accessories Page 507 **SE 8 sheet steel** Page 81

The system enclosure is based on the TS 8 platform. System accessories for interior installation in the TS 8 design can be used without restrictions.

Material and surface finish:

- Enclosure: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Door: Stainless steel 1.4301 (AISI 304), 2 mm, exterior brushed, grain size 400
- Rear panel: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Mounting plate: Sheet steel, 3 mm, zinc-plated
- Base: Stainless steel 1.4301 (AISI 304), 1.5 mm, uncoated

Protection category IP to IEC 60 529:

- IP 66

Protection category NEMA:

- NEMA 4X

Supply includes:

- Enclosure, solid top and sides
- Door(s)
- Door hinged on the right, may be swapped to the left
- Rear panel
- Mounting plate
- Base, solid
- Lock: 3 mm double-bit

Note:


- Due to the hardness of the material, we recommend using metal multi-tooth screws for the interior installation.

Approvals:

- UL
- cUL

Technical details:

Available on the Internet

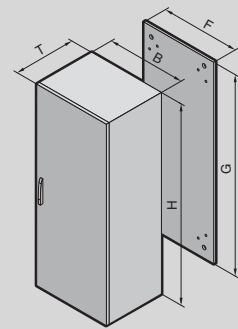

IP 66/NEMA 4X

Width (B) mm	Packs of	600	800	800	Page
Height (H) mm		1600	1800	2000	
Depth (T) mm		400	500	600	
Mounting plate width (F) mm		499	699	699	
Mounting plate height (G) mm		1496	1696	1896	
Model No.	1 pc(s).	5850.580	5852.580	5853.580	
Accessories					
Base/plinth trim panels, side, 100 mm	1 set(s)	8701.040	8701.050	8701.060	518
Base/plinth components, front and rear, 100 mm	1 set(s)	8701.600	8701.800	8701.800	518
Base/plinth trim panels, side, 200 mm	1 set(s)	8702.040	8702.050	8702.060	518
Base/plinth components, front and rear, 200 mm	1 set(s)	8702.600	8702.800	8702.800	518
Eyebolts	4 pc(s).	4568.500	4568.500	4568.500	586
Rail systems		from page	from page	from page	605
Cable clamp rails	2 pc(s).	4191.000	4192.000	4192.000	665
Sheet steel wiring plan pockets	1 pc(s).	4116.000	4118.000	4118.000	578
System lights		from page	from page	from page	634
Earth straps		see page	see page	see page	644
Metal multi-tooth screws	300 pc(s).	2486.300	2486.300	2486.300	625
Snap-on nut TS		see page	see page	see page	618
Cable duct for vertical TS section		see page	see page	see page	663
Door stay for escape routes	1 pc(s).	4583.500	4583.500	4583.500	578
Lock systems		from page	from page	from page	563