



## System accessories Page 507 SE 8 stainless steel Page 185

The system enclosure is based on the TS 8 platform. System accessories for interior installation in the TS 8 design can be used without restrictions.

### Material and surface finish:

- Enclosure: Sheet steel, 1.5 mm, dipcoat-primed, powder-coated on the outside, textured paint
- Door: Sheet steel, 2 mm, dipcoat-primed, powder-coated on the outside, textured paint
- Rear panel: Sheet steel, 1.5 mm, dipcoat-primed, powder-coated on the outside, textured paint

- Mounting plate: Sheet steel, 3 mm, zinc-plated
- Base: Sheet steel, 1.5 mm, dipcoat-primed and powder-coated, textured paint

### Colour:

- RAL 7035

### Protection category IP to IEC 60 529:

- IP 66

### Protection category NEMA:

- NEMA 4

### Supply includes:


- Enclosure, solid top and sides
- Door(s)
- Door hinged on the right, may be swapped to the left
- Mounting plate
- Base, solid
- Rear panel
- Lock: 3 mm double-bit

### Approvals:

- UL
- cUL

### Technical details:

Available on the Internet

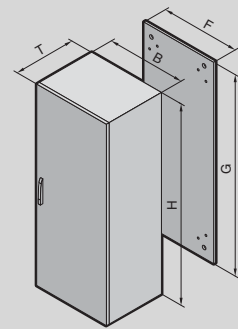

## IP 66/NEMA 4

Width (B) mm	Packs of	600	800	800	Page
Height (H) mm		1800	1800	2000	
Depth (T) mm		400	400	600	
Mounting plate width (F) mm		499	699	699	
Mounting plate height (G) mm		1696	1696	1896	
<b>Model No.</b>	1 pc(s).	<b>5830.580</b>	<b>5831.580</b>	<b>5834.580</b>	
Door(s)		1	1	1	

### Accessories

Accessories		600	800	800	Page
Base/plinth components, front and rear, 100 mm	1 set(s)	8601.600	8601.800	8601.800	513
Base/plinth trim panels, side, 100 mm	1 set(s)	8601.040	8601.040	8601.060	514
Base/plinth components, front and rear, 200 mm	1 set(s)	8602.600	8602.800	8602.800	513
Base/plinth trim panels, side, 200 mm	1 set(s)	8602.040	8602.040	8602.060	514
Eyebolts	4 pc(s).	4568.000	4568.000	4568.000	586
Rail systems		from page	from page	from page	605
TS punched section with mounting flange, 23 x 73 mm	4 pc(s).	8612.560	8612.580	see page	607
Cable entry plates	2 pc(s).	8800.060	8800.080	8800.080	650
Section for cable entry, rear	1 set(s)	8802.065	8802.085	8802.085	652
Cable clamp rails	2 pc(s).	4191.000	4192.000	4192.000	665
C rails 30/15	6 pc(s).	4944.000	4945.000	see page	612
Sheet steel wiring plan pockets		see page	see page	see page	578
180° hinges		see page	see page	see page	574
System lights		from page	from page	from page	634
Earth straps		see page	see page	see page	644
TS punched section without mounting flange, 45 x 88 mm	2 pc(s).	8612.660	8612.680	see page	608
TS punched rail 25 x 38 mm	2 pc(s).	8612.760	8612.780	see page	608
TS punched rail 18 x 38 mm		see page	see page	see page	609
Door stay for escape routes	1 pc(s).	4583.500	4583.500	4583.500	578
Lock systems		from page	from page	from page	561