


Fuse holders

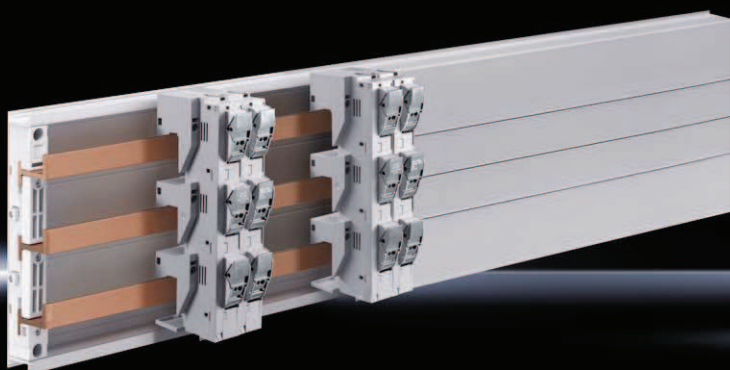

Busbar system Cat. 34, page 212

Material:

- Polyamide (PA 6.6)
- Fire protection corresponding to UL 94-V0

Colour:

- RAL 7035

Basis of test:

- UL 4248-4

Further technical information:

Available on the Internet

Rated operating current max. 30 A

| Fuse type (class) | Packs of | CC | Page |
|--|----------|-----------------|------|
| Rated operating current max. A | | 30 | |
| Rated operating voltage V, ~ | | 600, 3~ | |
| Number of poles | | 3-pole | |
| Fuse standard | | UL 248-4 | |
| Fuse size mm | | 10 x 38 | |
| Connection of round conductors mm ² | | 1.5 - 6 | |
| Connection of round conductors | | AWG 10 - 16 | |
| Width mm | | 27 | |
| Height mm | | 200 | |
| For bar systems with centre-to-centre spacing mm | | 60 | |
| For bar thickness mm | | 5 10 | |
| Model No. | 4 pc(s). | 9345.040 | |