


1

Anlaufscheiben,
selbstschmierend

Thrust bearings,
self-lubricating

Paliers de butée,
autolubrifiantes

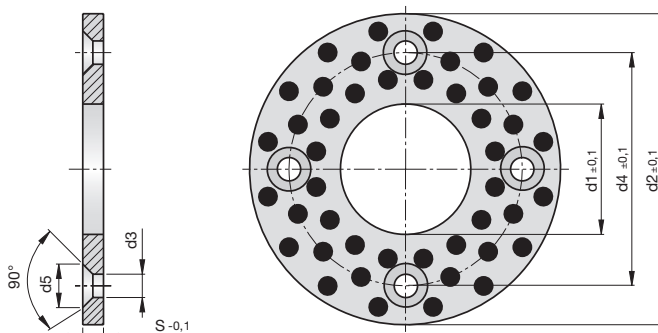

SN4189-

Mat.: Bronze
190-220 HB S10/3000
< 150 °C



SN4189-d1-d2



| d1 | d2 | d4 | S | d5 | d3 | Bohrungen Drillings Perçages |
|------|-----|------|----|------|-----|------------------------------------|
| 12,2 | 40 | 28 | 3 | - | - | - |
| 16,2 | 50 | 28 | 3 | - | - | - |
| 20,2 | 50 | 35 | 5 | 11,5 | 5,5 | 2 |
| 25,2 | 55 | 40 | 5 | 11,5 | 5,5 | 2 |
| 30,2 | 60 | 45 | 5 | 11,5 | 5,5 | 2 |
| 35,2 | 70 | 50 | 5 | 11,5 | 5,5 | 2 |
| 40,2 | 80 | 60 | 7 | 13,8 | 6,6 | 2 |
| 45,3 | 90 | 67,5 | 7 | 13,8 | 6,6 | 2 |
| 50,3 | 100 | 75 | 8 | 13,8 | 6,6 | 4 |
| 60,3 | 120 | 90 | 8 | 18,3 | 8,4 | 4 |
| 70,3 | 130 | 100 | 10 | 18,3 | 8,4 | 4 |
| 80,3 | 150 | 120 | 10 | 18,3 | 8,4 | 4 |